


Datasheet

RS Pro Grey Cat5e Ethernet Cable, Twisted Pair 300 V 1 → 100m

RS Stock No: **775-4079**

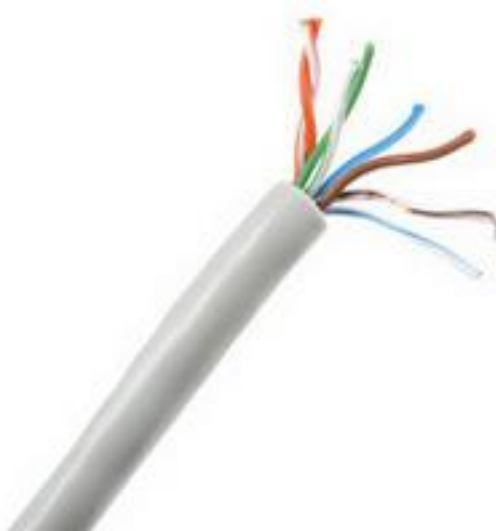

Features and Benefits

- Enhanced, high performance Cat5e cable for LAN applications or future proofing of structured cabling systems
- 25 pair, low smoke zero halogen version available
- UTP shielded

Specifications:

Attenuation	12.1 dB @ 16 MHz, 17.1 dB @ 31.25 MHz, 24.8 dB @ 62.5 MHz, 3.2 dB @ 1 MHz, 32 dB @ 100 MHz, 6 dB @ 4 MHz, 9.5 dB @ 10 MHz
Cable Shape	Twisted Pair
Capacitance	50 pF/m
Conductor Strand Type	Stranded
Core Strands	7/0.16 mm



ENGLISH

Length	100 m
Number of Strands	7
Outer Diameter	5.2 mm
Outer Sheath Material	PVC
Sheath Colour	Grey
Shield Type	UTP
Size of Strands	0.16 mm
Standards Met	IEC 60332.1, UL 1581 VW-1, RoHS Compliant
Voltage Rating	300 V
Conductor Material	Bare Copper
Insulator Material	PE