


Datasheet

T10 Filament Indicator Lamp

RS Stock number 106-420



Dimensions: (mm)

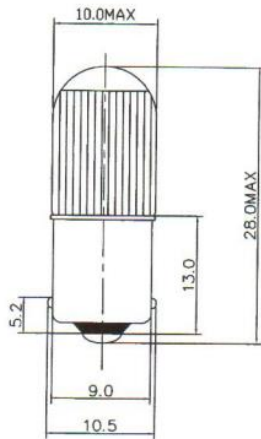

Structure

Bulb Type	T10x30
Bulb Diameter	Ø10.0Max
Length	28.0Max
Base Type	Ba9s

Design Characteristics

Voltage	220/250V
Amperage	1.8mA±10%
Gas Type	Neon Filled Gas
Life Hours	50,000Hours