


## Enclosure components – partitions

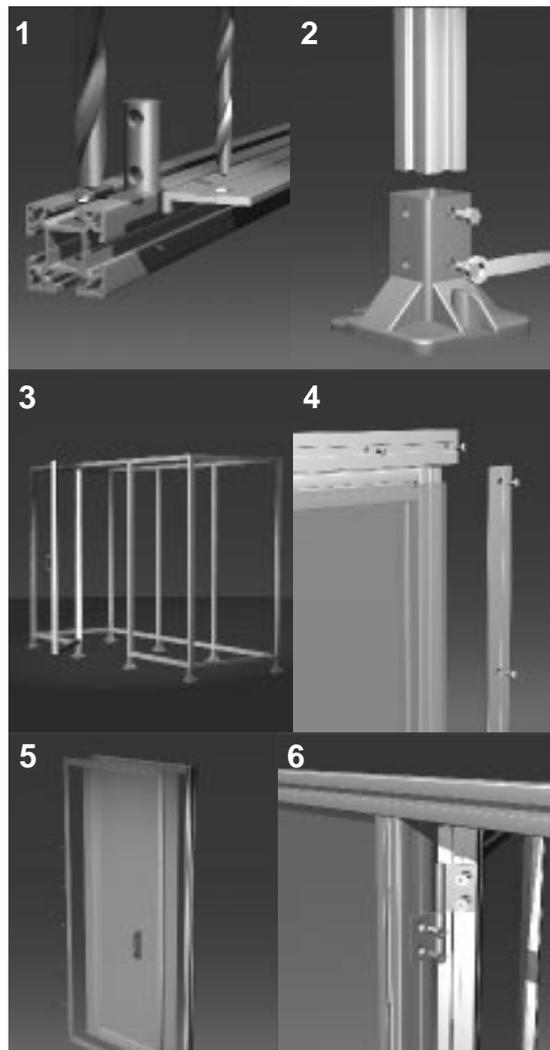

### Panels/nets mounted with enclosure profile


- Cut XCBL ..x44 and XCEP ..x5/10x44 to desired lengths: Drill holes for fastener yokes XCAF 44 and for assembly of the enclosure profiles (1).
- Mount XCFF 44x130 onto all vertical beams (2).
- Assemble the entire framework (3).
- Mount nets/panels with XCEP ..x5/10x44 onto the framework (4).
- Assemble the door framework and then the nets/panels. Premount the handle onto the XCEP ..x10x44 before assembling it onto the framework (5).
- Mount the hinge to the framework and then the door profile. Please note that it is necessary to mill away 5 mm from XCEP ..x10x44 before mounting the hinges (6).
- Finally, install the ball latch lock kit and security switch kit.



PO  
TR  
XS  
XL  
XM  
XH  
XK  
XW  
CA  
PAL  
XP  
XC  
XD  
XR  
FST  
APX  
IDX

## Enclosure profile

Profile for enclosures  
Aluminium, anodized  
For mounting panels and  
nets to all standard profiles  
with a min. width of 44 mm  
Mounting:  
MF6S 6×16 (for 6 mm  
panels)  
XCAN 6

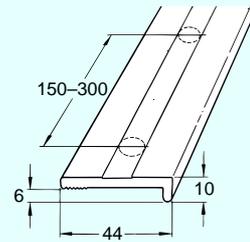


**XCEP 3×10×44**  
**XCEP L×10×44**

Edge profile, length 3 m  
Edge profile, length to order

**XCEP 3×5×44**  
**XCEP L×5×44**

Inner profile, length 3 m  
Inner profile, length to order

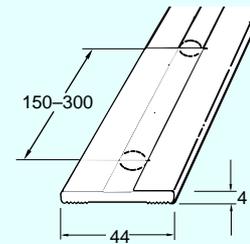


## Profile for sliding door

Profile for sliding door  
Aluminium, anodized  
Mounting:  
MLC6S 6×12  
XCAN 6 (profile), or  
MC6S 6×14  
BRB 6,4×12 and  
M6M 6 (angle bracket)


**XLFL 3**  
**XLFL L**

Length 3 m  
Length to order

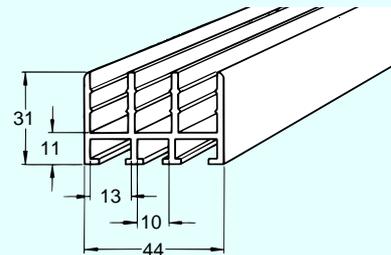

**XLFR 3**

Slide strip for sliding doors  
Length 3 m  
Polyvinyl chloride

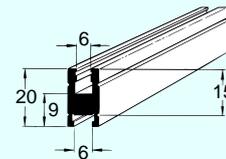

## Multiblock

<p><b>XCAM 14</b></p>	<p>Multiblock, assembly Including polyamide clamp and M6 square nut Polyamide</p>	
-----------------------	---	--






## Enclosure strips

<p><b>XCET 25</b></p>	<p>Rubber strip for panels Length 25 m EPDM rubber, black</p>	
<p><b>XCET 3 A</b></p>	<p>Rim strip Length 3 m Polyvinyl chloride, grey</p>	
<p><b>XCET 3 C</b></p>	<p>Net strip Polyvinyl chloride, grey Length 3 m</p>	
<p><b>XCET 3 D</b></p>	<p>Sliding door profile Length 3 m Polyvinyl chloride, grey</p>	

*New!*

PO  
TR  
XS  
XL  
XM  
XH  
XK  
XW  
CA  
PAL  
XP  
XC  
XD  
XR  
FST  
APX  
IDX

## Door accessories

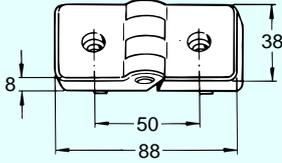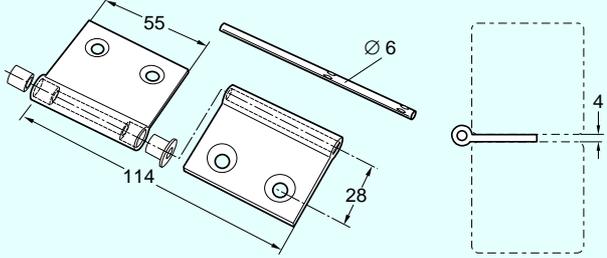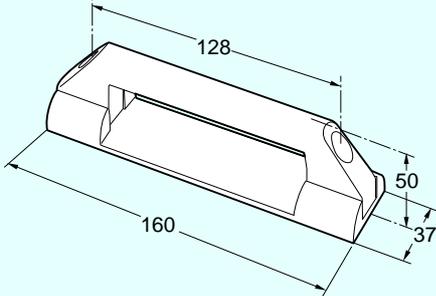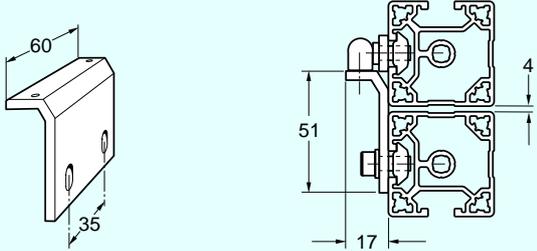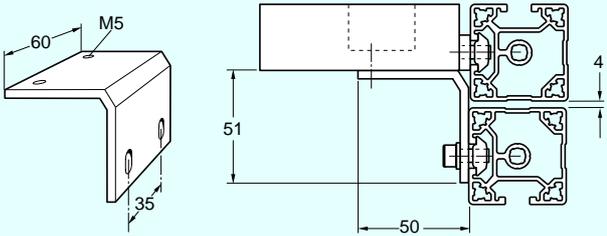
<p><b>XCAH 50</b></p> <p>Hinge Including rotatable guide lugs Polyamide Mounting: MLC6S 6×12 (2) XCAN 6 (2)</p>	
<p><b>XCAH 110 A</b></p> <p>Hinge kit Including the necessary mounting hardware Aluminium, anodized</p>	
<p><b>XDEH 160</b></p> <p>Handle assembly Including adapter plate for XC Polyamide Mounting: MC6S 5×20 (2) XCAN 5 (2)</p>	
<p><b>XCEL 60 B</b></p> <p>Ball latch lock kit Kit includes the necessary mounting hardware Aluminium, anodized</p>	
<p><b>XCEL 60 W</b></p> <p>Security switch kit Kit includes the necessary mounting hardware Aluminium, anodized For security switch Schmersal AZ 15/16-B1 Security switch is not included</p>	

## Door accessories

### XCEL 60 BA

Ball latch lock kit  
Aluminium, anodized  
Including ball latch and the  
necessary mounting hard-  
ware


*New!*

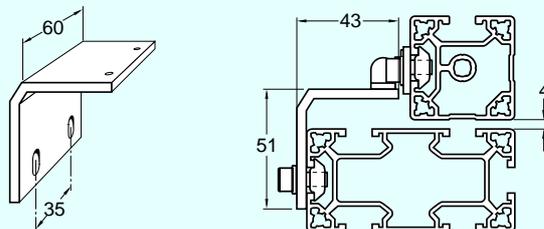

### XCEL 60 WA

Security switch kit  
Aluminium, anodized  
Including the necessary  
mounting hardware  
For security switch  
Schmersal AZ 15/16-B1  
Security switch is not in-  
cluded

*New!*

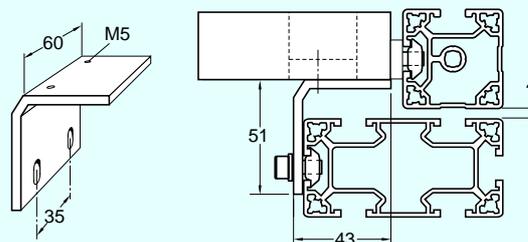

PO  
TR  
XL  
XL  
XM  
XH  
XK  
XW  
CA  
PAL  
XP  
XC  
XD  
XR  
FST  
APX  
IDX