

Features

- Stack Light Base Unit
- Direct mount
- Continuous Lighting
- No Flashing/Buzzer
- 60mm
- 24V DC
- IP65

RS PRO Signal Tower – Stack Light Base Unit, Direct Mount

RS Stock No.: 245-781



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

RS PRO Signal Tower – Stack Light Base Unit, Direct Mount, 24 V

Introducing the RS PRO 24V Signal Tower Light Base Unit – your ultimate solution for enhanced safety and productivity. This sleek and durable signal tower is designed to work seamlessly with flashing/buzzer units and LED modules, ensuring clear and effective communication even in harsh environments. Its robust construction is built to withstand tough conditions, providing reliability and longevity. The body unit offers quick and easy direct mounting, meeting all your signalling needs with efficiency and reliability

General Specifications

Light Effect	Continuous Lighting
Lens	Red/Amber/Green/Blue/White (Available Separately)
Fitting	Direct Mount
Housing Colour	Black
Lamp Include	No
Special Features	Easily customise and field configure LED units and sound modules
Supply Voltage	24V DC
Current Type	DC
Current Consumption	Max. 250mA
Dimensions	60 (w) x 60 (d) x 99mm (h)

Operation Environment Specifications

Maximum Temperature	-20°C
Minimum Temperature	+50°C


Approvals

Compliance/Certifications	CE/UL/UKCA/WEEE/FCC
Standards Met	RoHS Compliant
IP Rating	IP65


Outer Dimensions

With Buzzer Unit

(Unit : mm)

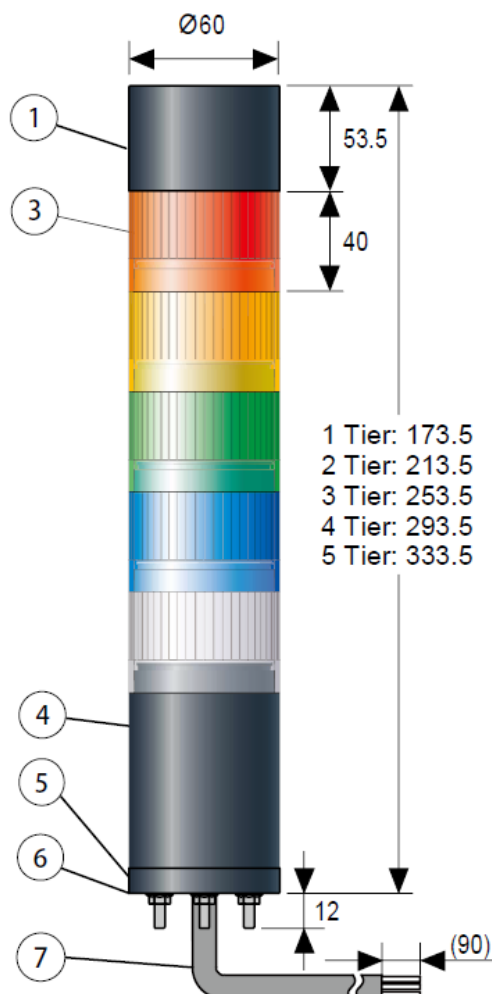

- Maximum Board Thickness : 7
- Cable Length : 1300
- Cable : UL2464 ($\varnothing 7.5$)
- Signal Wire & Power Supply Wire : AWG24

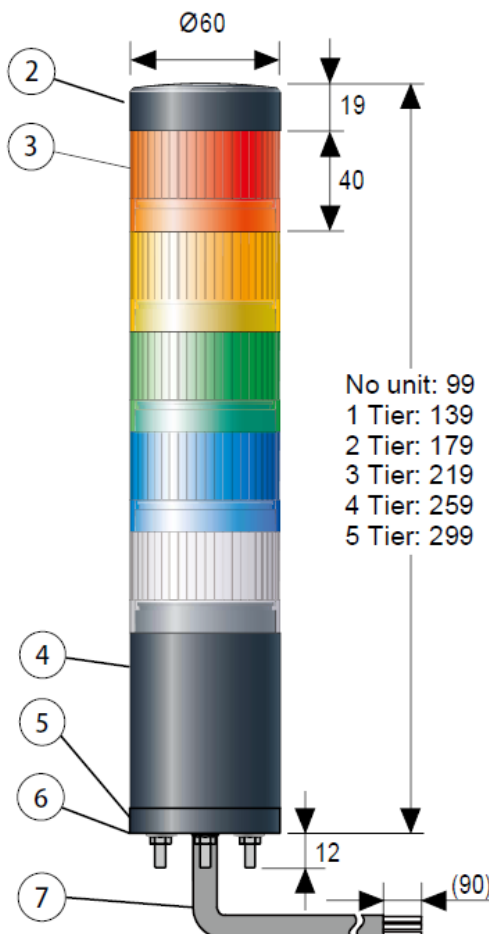


- Maximum Board Thickness : 7
- Cable Length : 1300
- Cable : UL2464 ($\varnothing 7.5$)
- Signal Wire & Power Supply Wire : AWG24


Number	Name	Material	UL Flammability
1	Buzzer Case	PC	V-2
2	Head Cover	PC	V-2
3	Globe	PC	V-2
4	Body	PC	V-2
5	Direct Mount Bracket	PC	V-2
6	Waterproof Packing	Silicone Rubber	-
7	Cable	PVC	VW-1



Accessory
Hexagon Nut with Flange (M4)
3pcs.

■ Mounting Dimensional Drawing

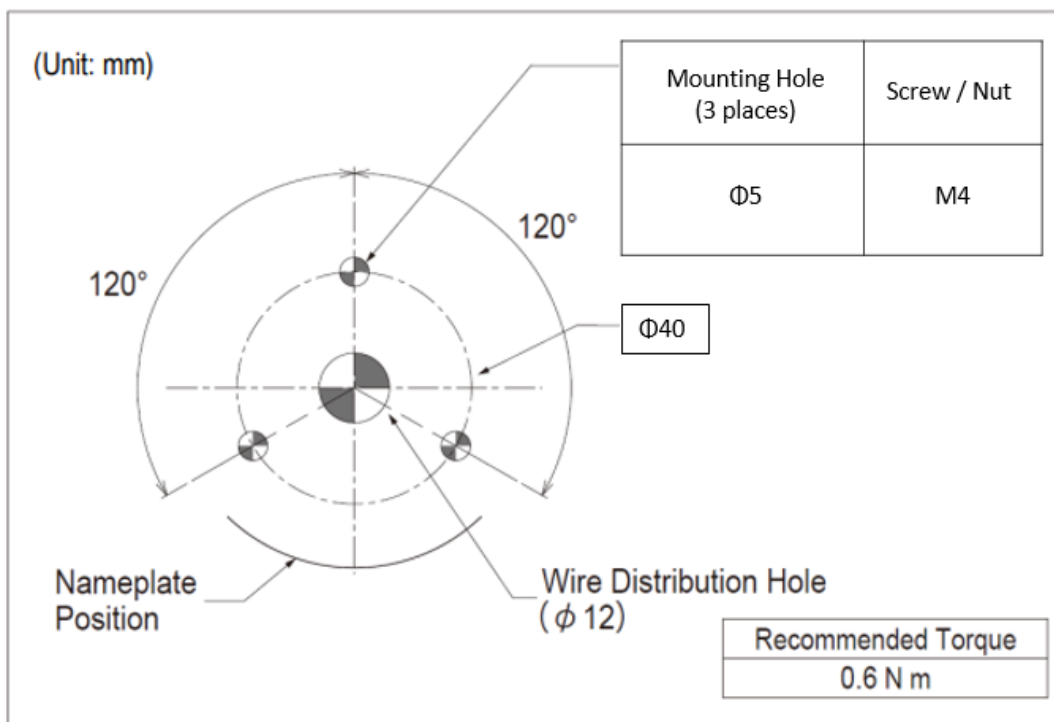

■ Wiring Diagram

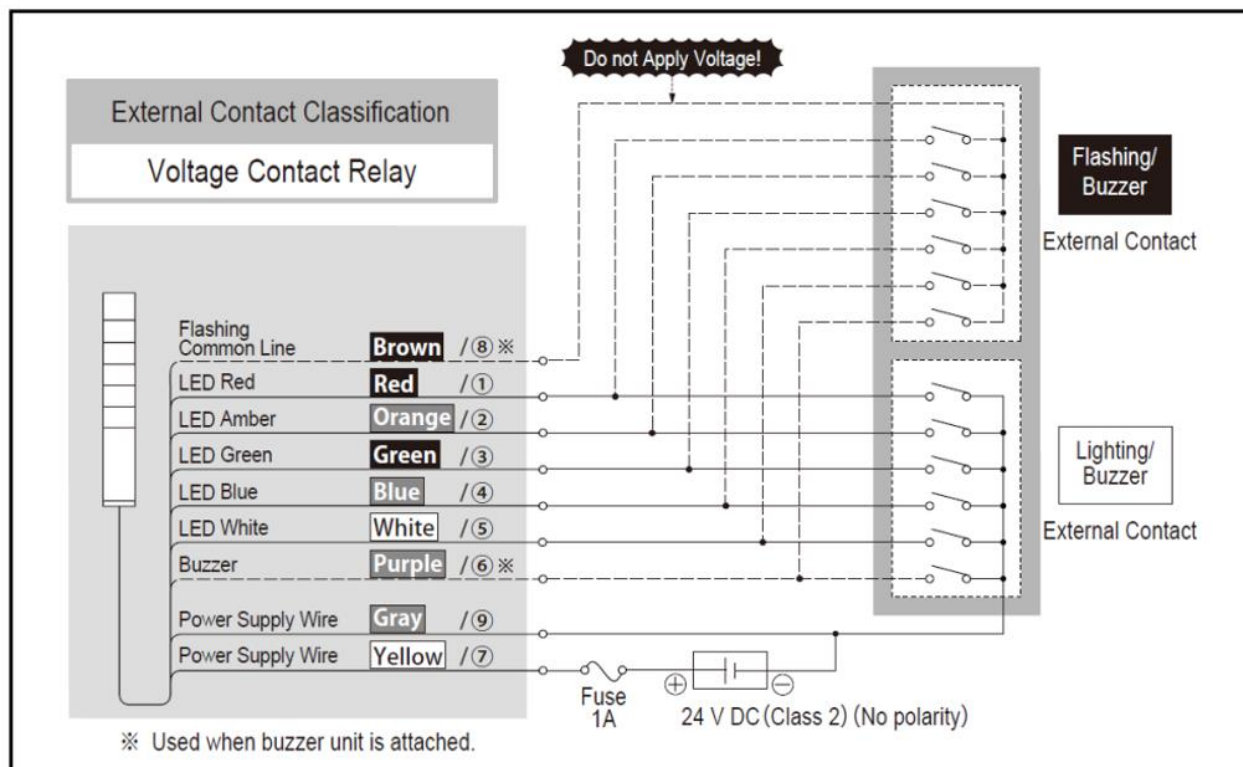

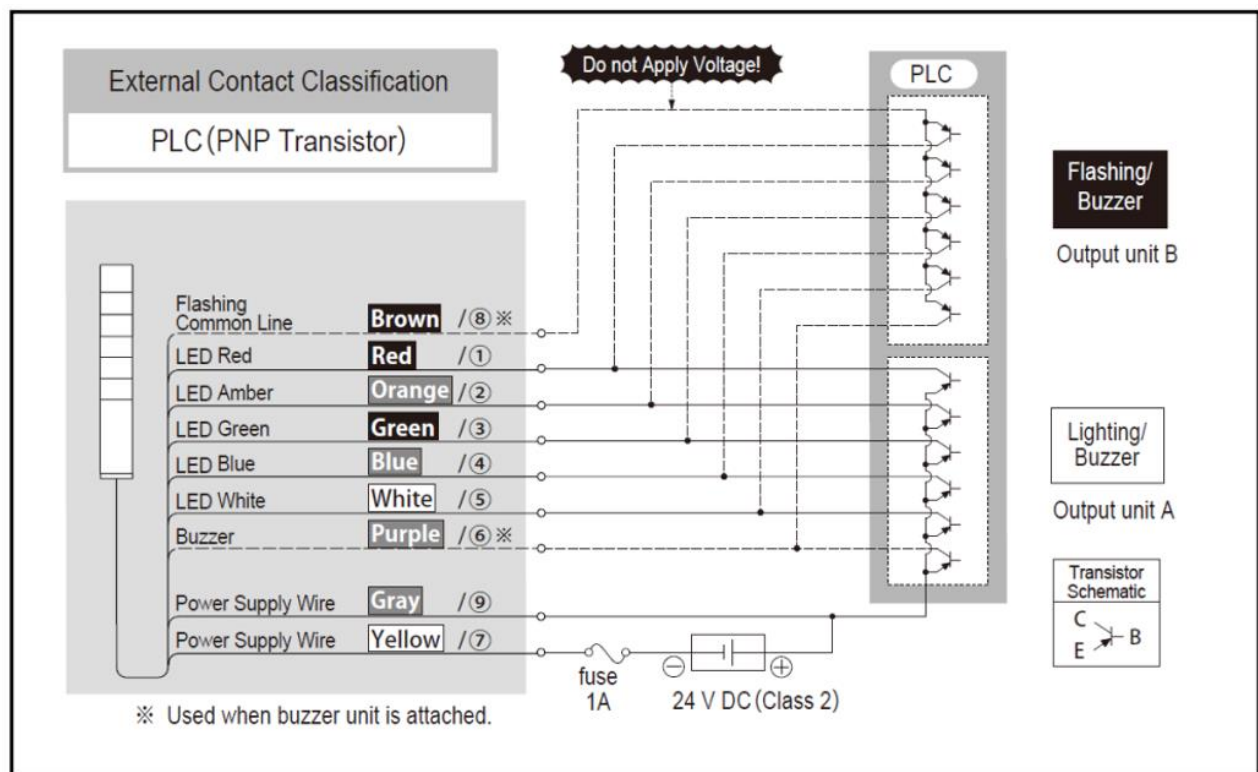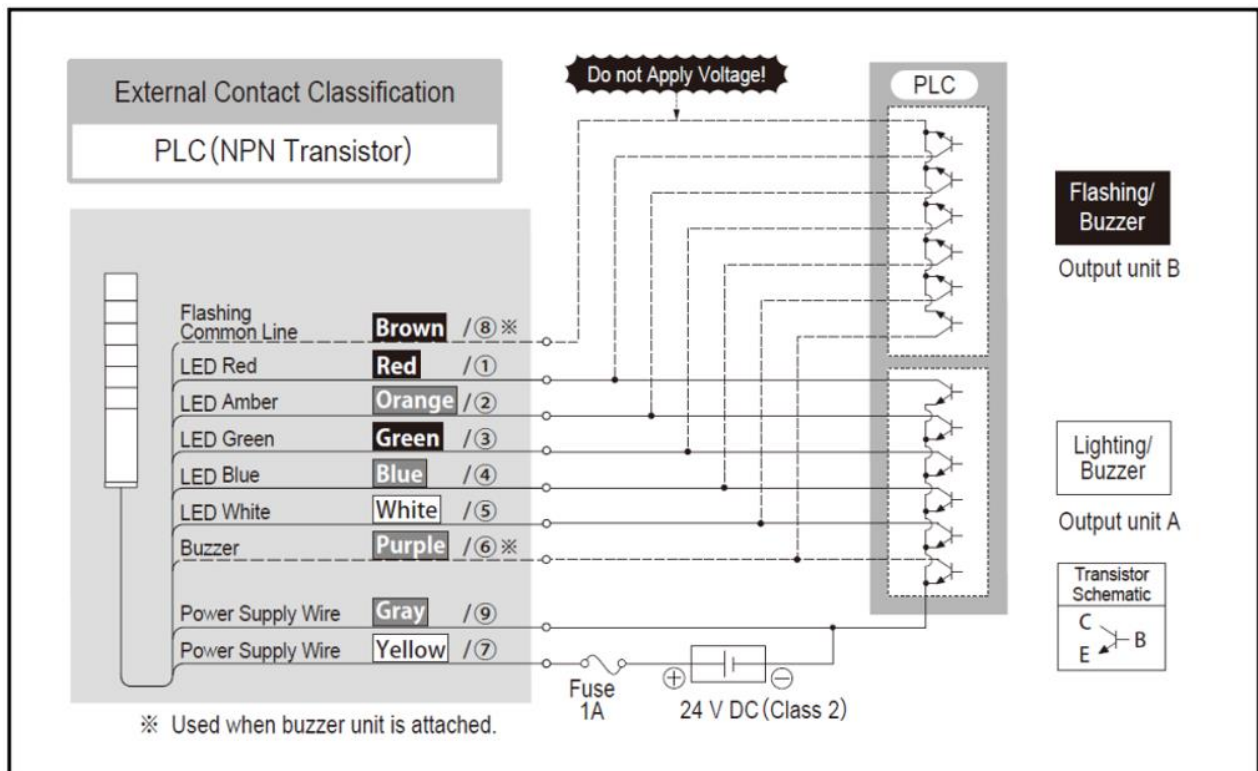

■ Accessories

LED Unit	
245-785	LED Unit, Red
245-787	LED Unit, Amber
245-788	LED Unit, Green
145-726	LED Unit, Blue
145-725	LED Unit, White

Buzzer Unit	
145-723	Flashing/Buzzer unit

Bracket	
145-727	Wall Mount Bracket