

Datasheet

RS PRO KCC 1113 tool for crimping BNC, TNC coaxial connectors on RG 58, RG 59, RG 62, RG 71, Thinnet


Stock No: 453-870




Features & Benefits:

- High strength, through hardened alloy steel construction
- Unique mechanism significantly reduces hand force
- Versatile and easy to customize for right hand or left hand users.
- Non-slip pad holds tool in place when leveraging on a work surface
- Full cycle crimp mechanism to ensure consistent, reliable crimp
- Ratchet release mechanism to clear miss-crimps and obstructions
- Precision eccentric adjustment for consistent performance and ability to calibrate
- Hole in handle allows attachment of safety strap
- Each tool has a unique serial number for traceability

Crimp Die Set

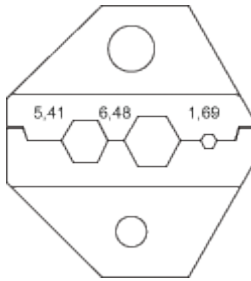

Crimp Profile

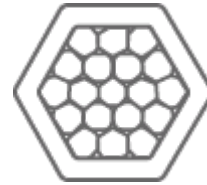

TECHNICAL DATA

Length: 204 mm/8.03"

Width: 22 mm/0.87"

Height: 76 mm/2.99"

Weight: 500 gr/1.1 lb

Hex crimp dimensions mm:

6.48 mm/5.41 mm/1.69 mm

Hex crimp dimensions inch:

0.255"/0.213"/0.067"

Connector: Coaxial connector

Description: For example BNC, TNC on RG 58, RG 59, RG 62, RG 71, Thinnet.

Life span, cycles: 50,000

Cables: RG108A/U, RG142B/U, RG210/U, RG223/U, RG302/U, RG58C/U, RG59B/U, RG62A/U, RG62B/U, RG71B/U