


Fibre optic diffuse reflection sensor

FT-00-M-E3

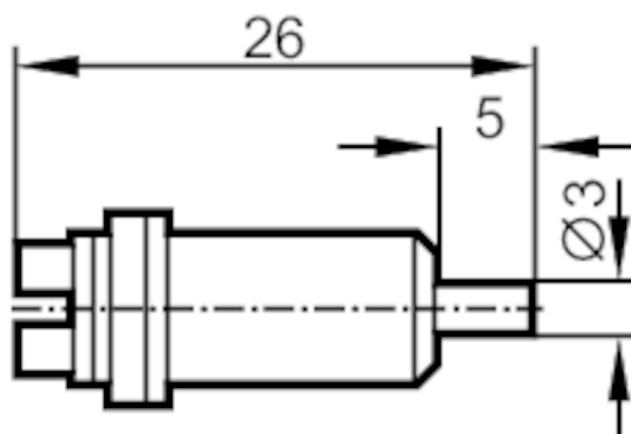

Application

Function principle

Diffuse reflection sensor

Application

For use in industrial environments

Detection zone

Range with fibre optic amplifier type

OCF; OKF; OUF

OCF (High Power)

Range fibre optics

[mm]

360

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

12.5

Version of sensing head

straight

Sensing head diameter

[mm]

3

Total length

[mm]

26

Fibre arrangement



E20078



Fibre optic diffuse reflection sensor

FT-00-M-E3

Fibre material	glass
Fibre head material	brass
Remarks	
Pack quantity	1 pcs.