

Features

- Non-Sparking
- Wrench types for adjustable wrench
- Jaw sizes from 18mm to 55mm
- Non-magnetic and highly corrosion resistant

RS PRO Beryllium Copper Adjustable Wrench, Non Sparking



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO Beryllium Copper Adjustable Wrench, Non-sparking

RS PRO series non sparking anti magnetic adjustable wrench. It is made of copper beryllium alloy.

Benefit and Features

- *Wrench types is adjustable wrench*
- Non-Sparking
- Non-magnetic and highly corrosion resistant

General Specifications

Jaw Capacity	See details below
Wrench Type	See details below
Non-Sparking	Yes
Overall Length	See details below
Handle Type	Beryllium Copper
Material	Beryllium Copper


Stock No.	Wrench Type	Jaw Capacity	Overall Length
0441269	Adjustable Wrench	18	150mm
0441270	Adjustable Wrench	24	200mm
0441272	Adjustable Wrench	30	250mm
0441273	Adjustable Wrench	36	300mm
0441275	Adjustable Wrench	46	375mm
0441276	Adjustable Wrench	55	450mm

Approvals

Declarations	REACH DoC
Standards Met	QB/T2613.8-2005

Similar Products

Stock No.	Brand	Product Name	Jaw Capacity	Overall Length	Non-Sparking
0441269	RS PRO	Adjustable Wrench	18	150mm	Yes
0441270	RS PRO	Adjustable Wrench	24	200mm	Yes
0441272	RS PRO	Adjustable Wrench	30	250mm	Yes
0441273	RS PRO	Adjustable Wrench	36	300mm	Yes
0441275	RS PRO	Adjustable Wrench	46	375mm	Yes
0441276	RS PRO	Adjustable Wrench	55	450mm	Yes
0441277	RS PRO	Pipe Wrench	30	250mm	Yes
0441279	RS PRO	Pipe Wrench	40	300mm	Yes
0441281	RS PRO	Pipe Wrench	50	350mm	Yes

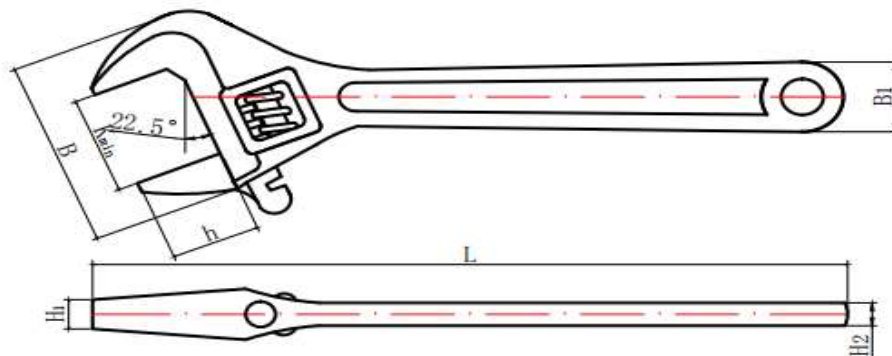

450	55	120	51	15	11.5	+1.0	-0.5	34
375	46	107.5	42	13.7	10	+1.0	-0.5	32
300	36	84.3	33	11.2	8.2	+1.0	-0.5	32
250	30	70.2	28	10.6	7.2	+1.0	-0.5	27
200	24	57.5	24	9	6.2	+1.0	-0.5	22
150	18	44.7	18	8	5.2	+1.0	-0.5	16
L ± 3	Kmin	B ± 2.5	h ± 1.5	H1 ± 1	H2	± H2		B1 ± 2