

**BOSCH**


Invented for life

Product data sheet

Power tools for trade & industry

Line Laser

PRO GLL 20-22 G

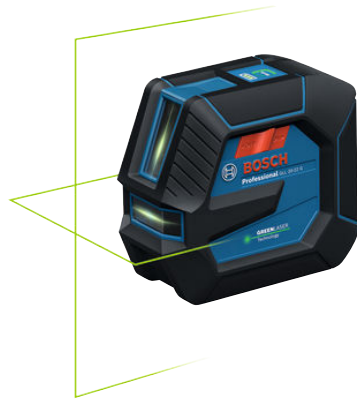

Easier alignment with our robust line laser

The most important data

Working range, value	20 m
Accuracy	± 0.3 mm/m
Self-levelling range	± 4°

Order number 0 601 065 600

Technical data

Additional data

Battery voltage	3.7 V
Dust and splash protection	IP 65
Working range, value	20 m
Accuracy	± 0.3 mm/m
Colour of laser line	green
Laser diode	500 – 540 nm, < 10 mW
Operating temperature	-10 – 50 °C
Storage temperature	-20 – 70 °C
Laser class	2
Self-levelling range	± 4°
Levelling time	4 s
Power supply	3.7 V Li-Ion battery (3000 mAh), 4 x 1.5 V LR6 (AA)
Operating time (max.)	8 h (Li-Ion) and 6 h (4 x AA) in cross line mode
Weight, approx.	0.56 kg
Projection	2 lines



BOSCH

Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- IP65 rating and rubber-enforced housing for dust and water resistance
- U-shaped laser window for a wider fan-angle of the horizontal line
- Dual power source lets you switch between BA 3.7V 3.0Ah XL Li-Ion battery and AA alkaline batteries to help eliminate downtime



PROTECTED TOOLS
Impact | Water | Dust



You can find more information about the deviations in the following link: <https://www.bosch-professional.com/ge/en/wac/>

