

APPLICATIONS



- Battery-powered devices
- High switching frequency SMPS
- IoT
- Wearable
- Portable devices
- Input filters

FEATURES

- Size 2.0mmx1.6mmx1.0mm
- Low Profile
- Low Audible Noise
- Molded Construction
- Soft Saturation
- Stable Over High Temperatures
- Low DCR
- Max Operating Temp +125°C
- RoHS/REACH-Compliant, Halogen-Free







ELECTRICAL CHARACTERISTICS

Parameter			Value	Unit
Inductance ⁽¹⁾	L	±20%	1.0	μH
Resistance	R_{DC}	Typ	50	mΩ
Resistance _{MAX}	$R_{DC\ MAX}$	Max	60	mΩ
Rated Current ⁽²⁾	I_R	Typ	3.3	A
Saturation Current _{25°C} ⁽³⁾	$I_{SAT\ 25°C}$	Typ	4.2	A
Saturation Current _{100°C} ⁽⁴⁾	$I_{SAT\ 100°C}$	Typ	4.2	A
Resonance Frequency	f_r	Typ	66	MHz

GENERAL SPECIFICATIONS


⁽¹⁾ Inductance	Measured at 100kHz, 100mA
⁽²⁾ Rated Current	Rated current will cause the coil temperature rise ΔT of 40K I_R measured with the inductor soldered in a single-layer PCB. Copper layer thickness 35μm Cu / PCB size 30x50mm. Temperature behavior dependent on circuit design, PCB layout, proximity to other components, and trace dimensions and thickness.
⁽³⁾ Saturation Current _{25°C}	Saturation current will cause L to drop from 30% at 25°C ambient temperature
⁽⁴⁾ Saturation Current _{100°C}	Saturation current will cause L to drop from 30% at 100°C ambient temperature
Temperature Test Condition	Electrical specifications measured at 25°C, 35% RH if not given differently
Operating Condition	Operating temperature: -40°C to +125°C (including temp rise) Should not exceed +125°C under worst-case operation conditions
Storage Condition	Tape and Reel packaging: -10°C to +40°C Humidity: <50% RH

TYPICAL PERFORMANCE CURVES

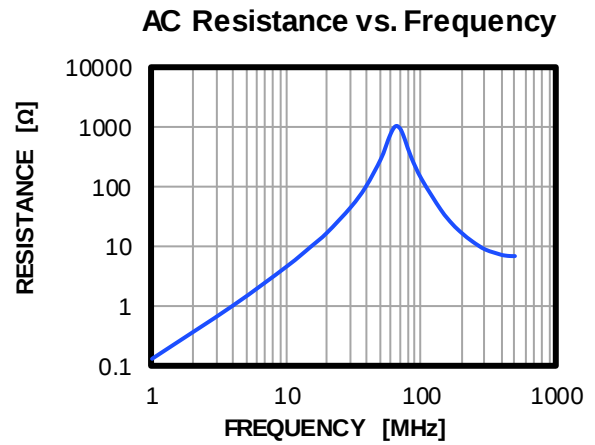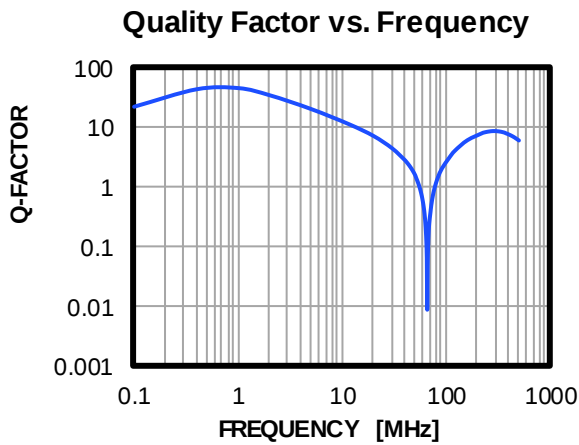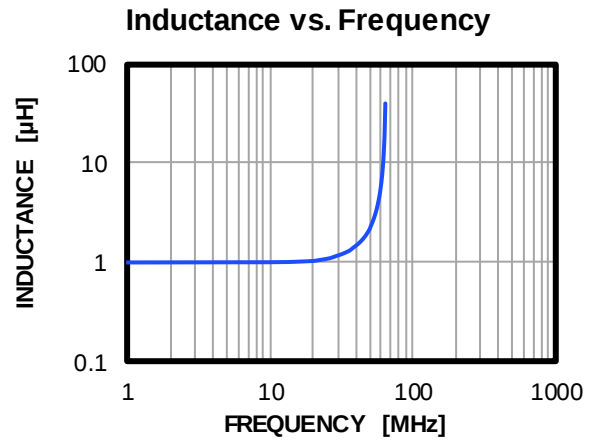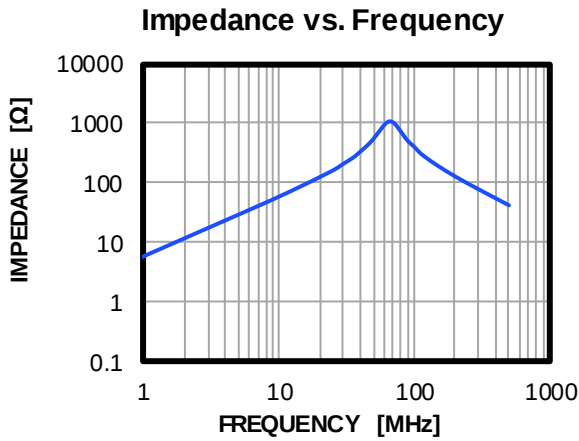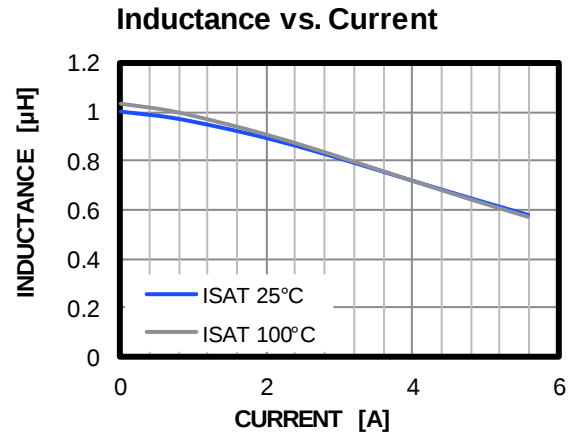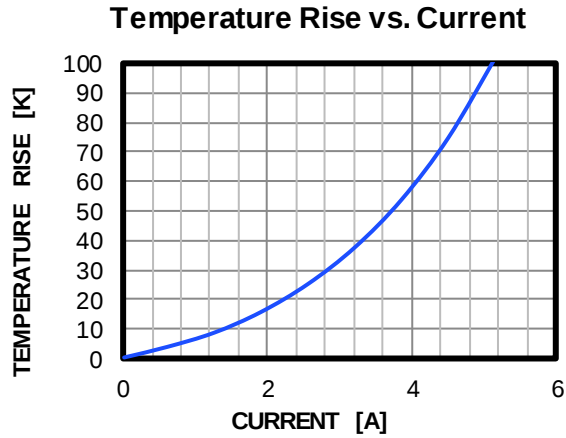


DIMENSIONS

PRODUCT PACKAGE

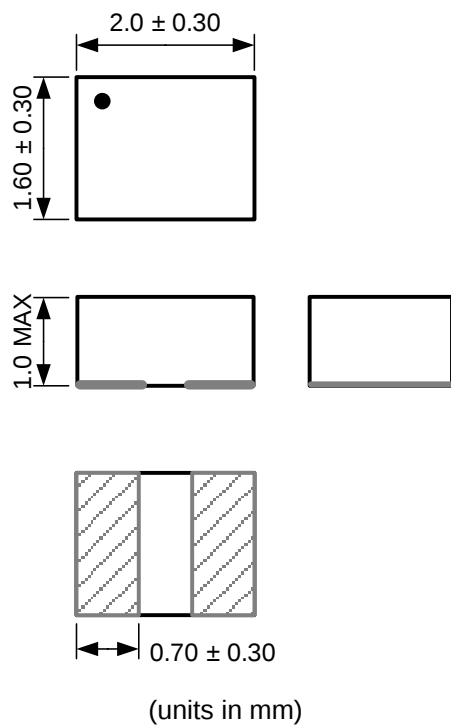

RECOMMENDED LAND PATTERN

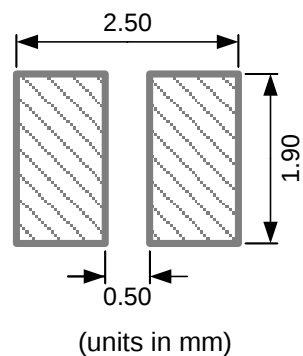

TOP MARKING

Marking

Start of Winding . (dot)

ORDERING INFORMATION

Part Number	$L^{(1)}$ ±20% (μH)	R_{DC} Typ (mΩ)	$I_R^{(2)}$ Typ (A)	$I_{SAT\ 25^\circ C}^{(3)}$ Typ (A)	$I_{SAT\ 100^\circ C}^{(4)}$ Typ (A)
MPL-AT2010-R47	0.47	27	4.5	5.7	5.7
MPL-AT2010-R68	0.68	41	3.6	4.9	4.9
MPL-AT2010-1R0	1.0	50	3.3	4.2	4.2
MPL-AT2010-1R5	1.5	85	2.4	3.2	3.2
MPL-AT2010-2R2	2.2	125	2.0	2.6	2.6
MPL-AT2010-4R7	4.7	215	1.5	1.9	1.9

GENERAL SPECIFICATIONS

(1) Inductance	Measured at 100kHz, 100mA
(2) Rated Current	Rated current will cause the coil temperature rise ΔT of 40K <i>I_R measured with the inductor soldered in a single-layer PCB. Copper layer thickness 35μm Cu / PCB size 30x50mm. Temperature behavior dependent on circuit design, PCB layout, proximity to other components, and trace dimensions and thickness.</i>
(3) Saturation Current 25°C	Saturation current will cause L to drop from 30% at 25°C ambient temperature
(4) Saturation Current 100°C	Saturation current will cause L to drop from 30% at 100°C ambient temperature
Temperature Test Condition	Electrical specifications measured at 25°C, 35% RH if not given differently
Operating Condition	Operating temperature: -40°C to +125°C (including temp rise) Should not exceed +125°C under worst-case operation conditions
Storage Condition	Tape and Reel packaging: -10°C to +40°C Humidity: <50% RH

REVISION HISTORY

Revision #	Revision Date	Description	Pages Updated
1.0	7/11/2019	Initial Release	-
1.1	8/1/2019	Updated Impedance vs. Frequency Curve	2
1.2	7/7/2023	Updated the I_R (Typ) and f_r (Typ) values, and made minor formatting edits in the Electrical Characteristics section	1
		Updated all the Typical Performance Curves	2
		Reordered the Dimensions section; updated the Product Package and Recommended Land Pattern images	3
		Updated the following values in the Ordering Information section: • MPL-AT2010-R47: Updated I_R (Typ) • MPL-AT2010-R68: Updated I_R (Typ) • MPL-AT2010-1R0: Updated I_R (Typ) • MPL-AT2010-1R5: Updated R_{DC} (Typ) • MPL-AT2010-2R2: Updated R_{DC} (Typ), I_R (Typ), I_{SAT} 25°C (Typ), and I_{SAT} 100°C (Typ)	4

Notice: The information in this document is subject to change without notice. Please contact MPS for current specifications. Users should warrant and guarantee that third-party Intellectual Property rights are not infringed upon when integrating MPS products into any application. MPS will not assume any legal responsibility for any said applications.