

Datasheet

RS, 100m Telephone Cable, Unshielded, 26 Silver Sheath, 4 Strands 150 V, 0.14 mm² CSA

RS Stock No. 749-2507



Product Description

Application:

For communication and signal control systems.

Reference Standard


Customer's sample spec.and the general standard

Multi-construction

4

	Cable	Construction
Conductor		Bare Copper
Construction		0.16±0.005x7
Stranded Dia.(±0.01mm)		0.49
Insulation		PE
Thickness		0.23
Insulation Dia.(±0.05mm)		0.95
Insulation Color		1,Black; 2,Red; 3,Green;4,Yellow
Filler		Chalk
Jacket		PVC
Thickness(mm)		0.60
Dia.(±0.15mm)		5.1×2.5
Jacket Color		Silver Grey(RAL9023)
Marking		
No Marking		
PACKAGING		
100M Coil		
8Pcs/Box		

Design

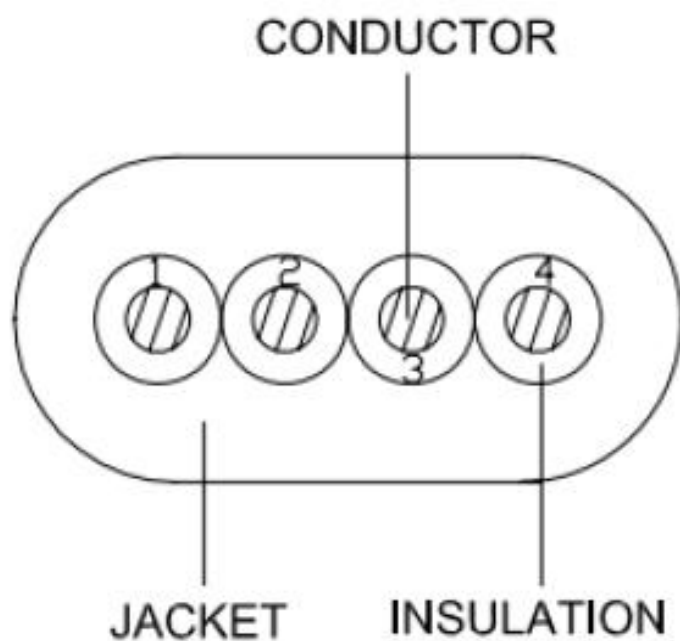

Electrical Characteristics

Max. Conductor DC Resistance at 20 °C (Ω /Km)	132
Min. Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-20 to +60
Rated Voltage(V)	150