


1646776 DSBG-80-125-PPVA-N3 standards-based cylinder - Series: All

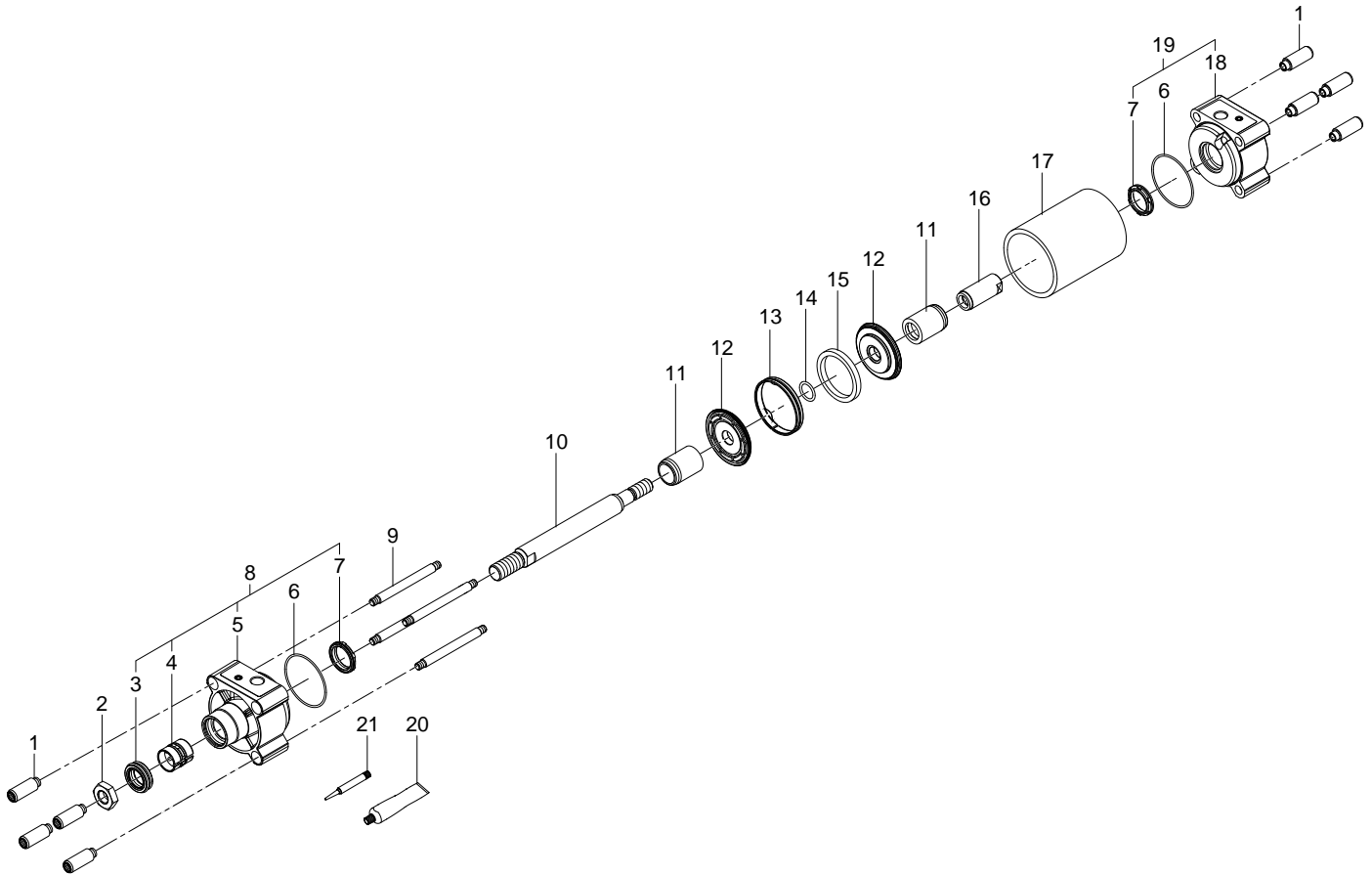

1646776 DSBG-80-125-PPVA-N3 standards-based cylinder - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	753092	DSBC/G- 80- - Set of wearing parts	Spare parts: 3, 6, 7, 12, 13, 14, 20, 21 Replacing the wearing parts	1	PC
1	1279719	DSBG-80/100 Collar nut	Tightening torque 17 Nm / 12.5 lbf ft Use locking compound. See position 21	8	PC
2	200198	DIN 439-B-M20X1,5-04 Hex nut		1	PC
3	232938	WIFC2-25X35X11,2-TPE-U Wiper seal	Grease using during assembly. See position 20	1	PC
4	5211165	DSBX-80/100 Bearing	Grease using during assembly. See position 20	1	PC
5		DSBC/G-80-PPV:CO Bearing cap	Not available separately, see position 8	1	PC
6		B-80X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 20	2	PC
7		DIFC1-30X40X7,8-TPE-U Buffer seal	Not available separately, see position 8+19+999 Grease using during assembly. See position 20	2	PC
8	1263039	DSBC/G-80-PPV Bearing cap module		1	PC
9	1380117	DSBG-80- Tie rod	When ordering please specify the stroke (see type plate)	4	PC
10	753078	DSBG-YP-80- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
11	332090	80/100 PPV Buffer sleeve		2	PC
12		BA-K01D-080 Piston module	Not available separately, see position A	2	PC
13		BA-K01F-080 Guiding band	Not available separately, see position A	1	PC
14		B-14X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 20	1	PC
15	4760182	76,9X58X6BA-K01M-080 Ring magnet		1	PC
16	711418	M14-D80/100 Threaded coupling	Tightening torque 60 Nm / 44.3 lbf ft Use locking compound. See position 21	1	PC
17		DSBG-F-80- -CA Cylinder barrel	Not available Grease using during assembly. See position 20	1	PC
18		DSBC/G-80-PPV:CO End cap	Not available separately, see position 19	1	PC
19	1297505	DSBC/G-80-PPV End cap module		1	PC
20	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
21	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC