



Figure similar

FOOT -OPERATED BUTTON, SINGLE PEDA L(WITHOUT LATCHING), CABLE ENTRY 1X(M20X1,5) METAL CASING IP65, 1 NO + 1 NC WITHOUT PROTECTIVE COVER

Product designation	momentary-contact foot switch
General technical data:	
Protection class IP	IP65
Equipment marking	
<ul style="list-style-type: none"> • acc. to DIN EN 61346-2 • acc. to DIN EN 81346-2 	S S
Number of switching steps	1
Number of the actuation pedals	1
Operating current at AC-15	
<ul style="list-style-type: none"> • at 230 V Rated value • at 400 V Rated value 	16 A 16 A
Enclosure:	
Material of the enclosure	metal
Color	
<ul style="list-style-type: none"> • of the enclosure • of top part of the enclosure 	black grey
Safety related data:	
B10 value with high demand rate acc. to SN 31920	1 000 000
Proportion of dangerous failures	
<ul style="list-style-type: none"> • with low demand rate acc. to SN 31920 • with high demand rate acc. to SN 31920 	50 % 50 %
Failure rate [FIT] with low demand rate acc. to SN 31920	100 FIT

T1 value for proof test interval or service life acc. to IEC 61508	20 y
--------------------------------------------------------------------	------

Mechanical data:

Cable entry type	M20 x 1.5
------------------	-----------







Ambient conditions:



Ambient temperature	-25 ... +80 °C
• during operation	

Installation/ mounting/ dimensions:

Mounting type	screw fixing
Height	220 mm
Width	70 mm
Depth	61 mm

Certificates/ approvals:

General Product Approval	Declaration of Conformity	Shipping Approval
 CCC	 EG-Konf.	 ABS
 CSA		 LRS

Shipping Approval	other
 PRS	 RINA

[other](#) [Confirmation](#)

Further information



Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)
<http://www.siemens.com/industrymall>

Cax online generator
<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SE29020AB20>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3SE29020AB20>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)
http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SE29020AB20&lang=en

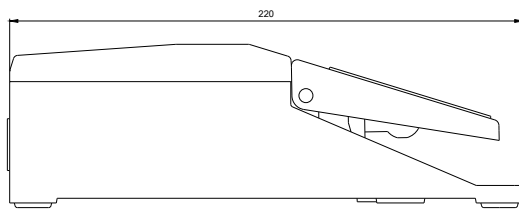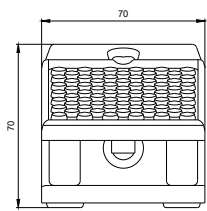

last modified:

27.04.2015