



Receptacle

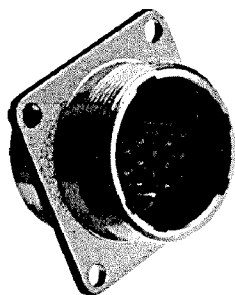

JR21RK-16P

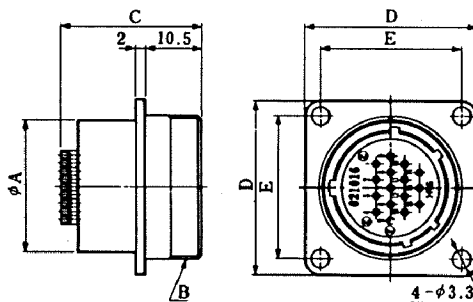

(An example in shape)

| HRS No. | Part No. | No. of pins | ϕA | B | C | D | E | JIS No. |
|------------|------------|-------------|----------|-------|------|----|----|----------------|
| 114-0517-7 | JR13RK-3P | 3 | 15.9 | M18x1 | 26.6 | 26 | 20 | CNRO1SRM013003 |
| 114-0518-0 | JR13RK-5P | 5 | 15.9 | M18x1 | 26.1 | 26 | 20 | CNRO1SRM013005 |
| 114-0519-2 | JR16RK-7P | 7 | 19.9 | M22x1 | 26.6 | 29 | 23 | CNRO1SRM016007 |
| 114-0520-1 | JR16RK-10P | 10 | 19.9 | M22x1 | 26.1 | 29 | 23 | CNRO1SRM016010 |
| 114-0521-4 | JR21RK-10P | 10 | 23.9 | M26x1 | 26.6 | 32 | 26 | CNRO1SRM021010 |
| 114-0522-7 | JR21RK-16P | 16 | 23.9 | M26x1 | 26.1 | 32 | 26 | CNRO1SRM021016 |
| 114-0523-0 | JR25RK-16P | 16 | 27.9 | M30x1 | 26.6 | 35 | 29 | CNRO1SRM025016 |
| 114-0524-2 | JR25RK-24P | 24 | 27.9 | M30x1 | 26.1 | 35 | 29 | CNRO1SRM025024 |
| 114-0558-4 | JR25RK-4P | 4 | 27.9 | M30x1 | 28 | 35 | 29 | ————— |
| 114-0560-6 | JR25RK-5P | 5 | 27.9 | M30x1 | 26.6 | 35 | 29 | ————— |
| 114-0562-1 | JR25RK-8P | 8 | 27.9 | M30x1 | 26.6 | 35 | 29 | ————— |

| HRS No. | Part No. | No. of pins | ϕA | B | C | D | E | JIS No. |
|------------|------------|-------------|----------|-------|------|----|----|----------------|
| 114-0525-5 | JR13RK-3S | 3 | 15.9 | M18x1 | 28 | 26 | 20 | CNRO1SRF013003 |
| 114-0526-8 | JR13RK-5S | 5 | 15.9 | M18x1 | 27 | 26 | 20 | CNRO1SRF013005 |
| 114-0527-0 | JR16RK-7S | 7 | 19.9 | M22x1 | 28 | 29 | 23 | CNRO1SRF016007 |
| 114-0528-3 | JR16RK-10S | 10 | 19.9 | M22x1 | 27 | 29 | 23 | CNRO1SRF016010 |
| 114-0529-6 | JR21RK-10S | 10 | 23.9 | M26x1 | 28 | 32 | 26 | CNRO1SRF021010 |
| 114-0530-5 | JR21RK-16S | 16 | 23.9 | M26x1 | 27 | 32 | 26 | CNRO1SRF021016 |
| 114-0531-8 | JR25RK-16S | 16 | 27.9 | M30x1 | 28 | 35 | 29 | CNRO1SRF025016 |
| 114-0532-0 | JR25RK-24S | 24 | 27.9 | M30x1 | 27 | 35 | 29 | CNRO1SRF025024 |
| 114-0559-7 | JR25RK-4S | 4 | 27.9 | M30x1 | 28 | 35 | 29 | ————— |
| 114-0561-9 | JR25RK-5S | 5 | 27.9 | M30x1 | 27.8 | 35 | 29 | ————— |
| 114-0563-4 | JR25RK-8S | 8 | 27.9 | M30x1 | 27.8 | 35 | 29 | ————— |