


FEATURES

- **Nylon Material:** Provides excellent strength and flexibility for secure bundling
- **Length of 203 mm:** Suitable for a wide range of cable sizes and applications
- **Maximum Bundle Diameter of 52 mm:** Accommodates larger cable bundles
- **Tensile Strength of 22 kg:** Ensures reliable and strong fastening
- **UL 94 V-2 Fire Behaviour:** Offers flame retardant properties for enhanced safety
- **Maximum Operating Temperature of 150 °C:** Suitable for high-temperature environments
- **Width of 4.6 mm:** Provides a balance of strength and flexibility

RS PRO 203 mm Nylon Cable Tie, Non-Releaseable

RS Stock No: 656-084

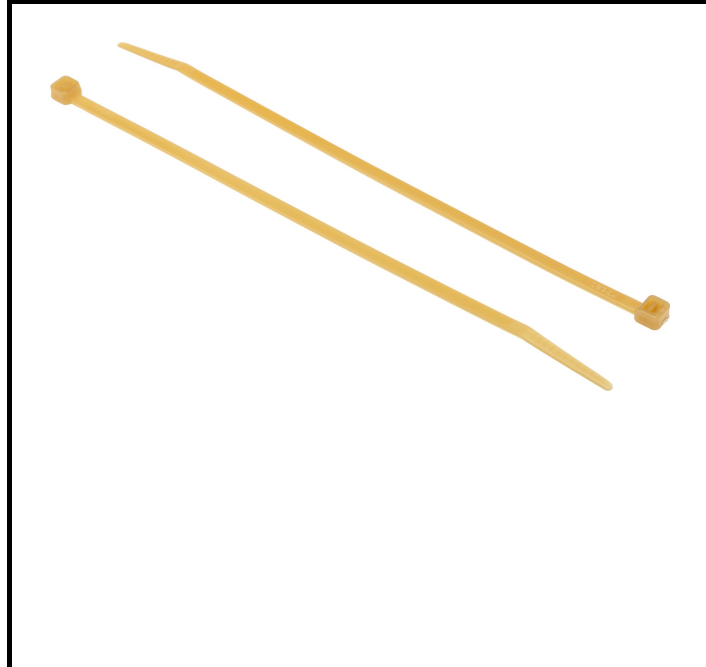

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a robust and reliable cable tie solution designed for secure bundling and organising of cables and wires. This non-releasable cable tie is ideal for applications requiring a permanent fastening solution, providing strength and durability in various environments.

General Specifications

Colour	Light Brown
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

Mechanical Specifications

Length	203 mm
Material	Nylon
Maximum Bundle Diameter	52 mm
Width	4.6 mm

Operation Environment Specifications

Maximum Operating Temperature	150 °C
-------------------------------	--------

Approvals

Standards/Approvals	RoHS, UL94V-2
---------------------	---------------

