


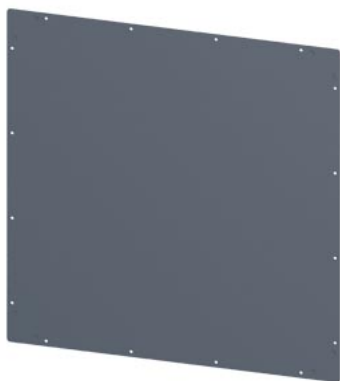

SIVACON, Roof, Closed, IP40, W: 800 mm, T: 800 mm, zinc-plated

Model			
product brand name		SIVACON	
product designation		top plate	
design of the product		Closed	
design of the surface		zinc plated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
Suitability			
suitability for use for outside use		No	
Product details			
product component			
• cable entry		No	
• ventilation		No	
Mechanical Design			
width		800 mm	
depth		800 mm	
net weight		7.9 kg	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1088-2UD10-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1088-2UD10-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1088-2UD10-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

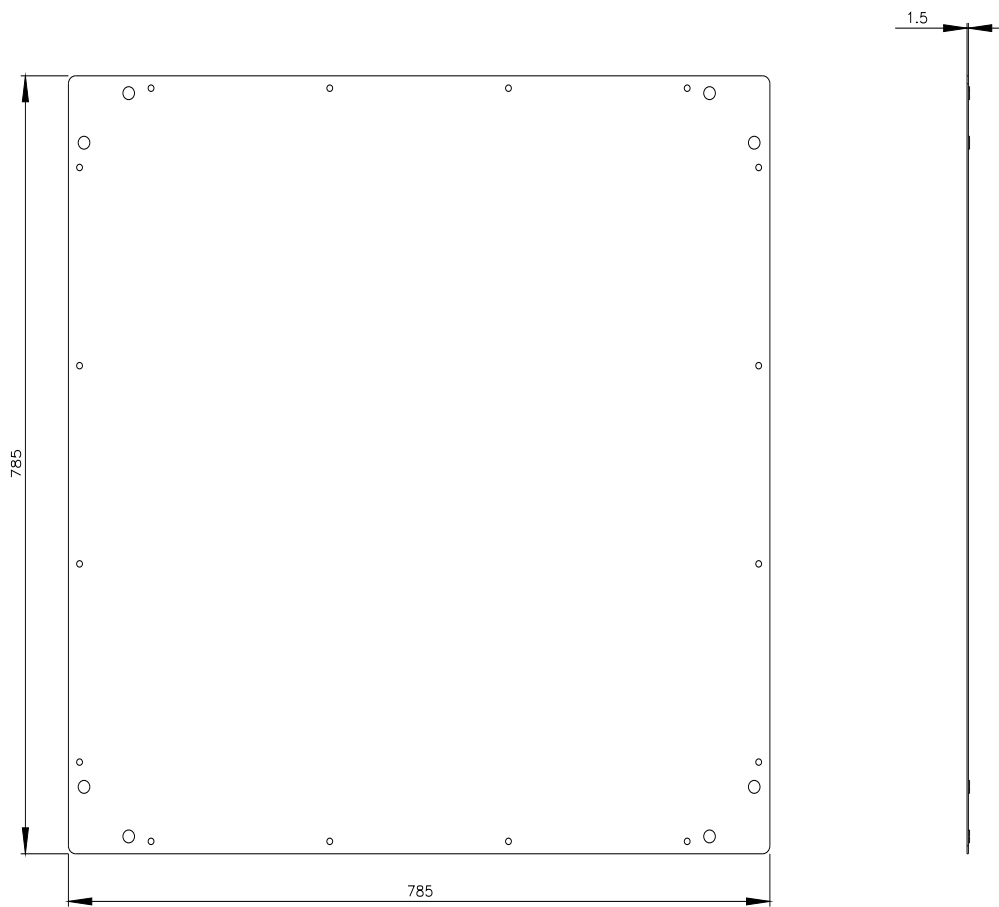

last modified:

7/24/2023 

