




4-Port USB 3.0 Hub

TU3-H4 (v3.0R)


- Easy installation
- Add four SuperSpeed 5Gbps USB 3.0 ports
- Convenient 1m (3 ft.) USB 3.0 cable
- Backward compatible with USB 2.0 and 1.1 devices
- Full power for all USB ports with included power adapter

TRENDnet's 4-Port USB 3.0 Hub, model TU3-H4, instantly adds four 5Gbps SuperSpeed USB 3.0 ports to a computer. Easy installation – simply plug in flash drives, printers, scanners and other USB 3.0 devices at speeds ten times faster than a USB 2.0 connection. The TU3-H4 USB 3.0 hub is also backwards compatible with USB 2.0 and 1.1 devices.

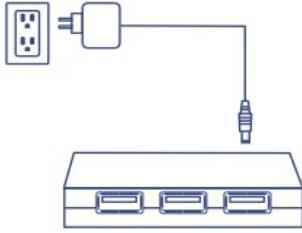


Included Power Adapter

Power adapter provides a total power of 20W.

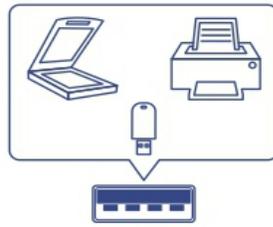


USB 3.0

Easily connect up to four USB 3.0 devices to a USB 3.0 enabled desktop or notebook PC.

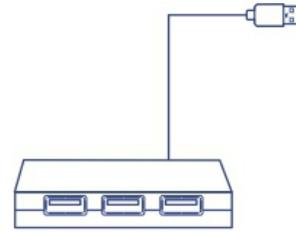

USB Cable

Included 1m (3 ft.) USB 3.0 cable accommodates most installation scenarios.

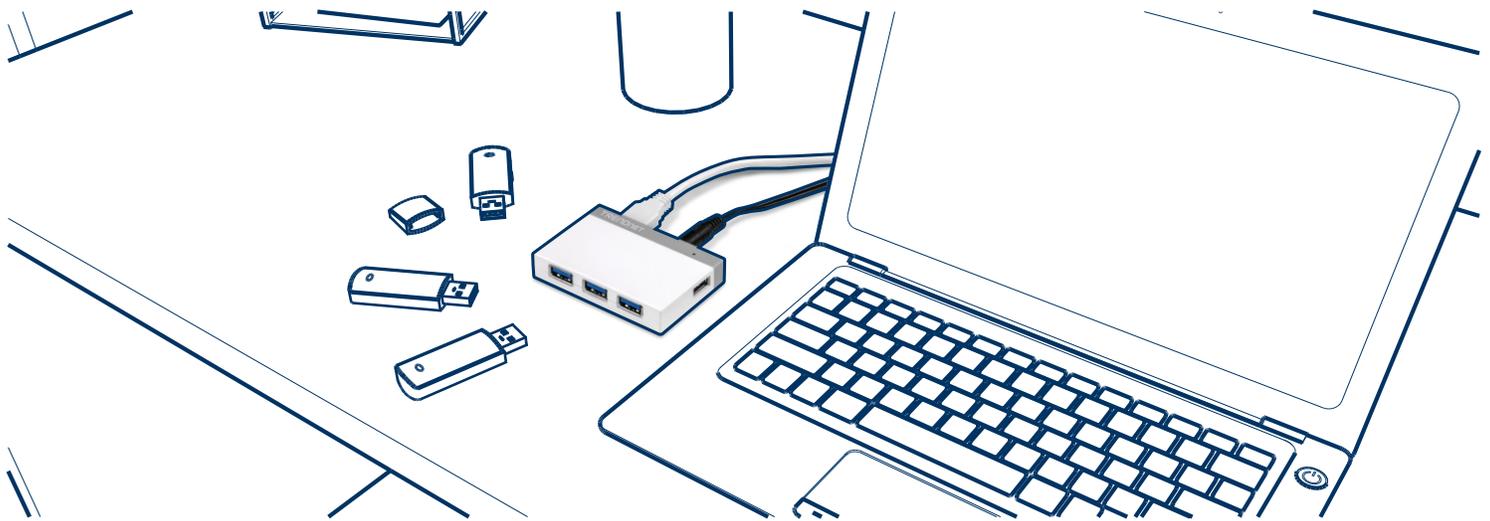

Easy Setup

No CD installation



Operating Systems

Compatible with Windows, Mac and Linux operating systems



Power Adapter

Power adapter provides a total power of 20W



USB 3.0

Easily connect up to four USB 3.0 devices to a USB 3.0 enabled desktop or notebook PC



Backwards Compatibility

USB 3.0 hub is compatible with USB 2.0 and 1.1 devices



Installation Flexibility

Included 1m (3 ft.) USB 3.0 cable accommodates most installation scenarios.



LED Indicator

LED indicator confirms USB connectivity

Specifications

Standards	<ul style="list-style-type: none"> • USB 3.0 • USB 2.0 • USB 1.1
Interfaces	<ul style="list-style-type: none"> • 4 x Type-A USB 3.0 ports • 1 x Type-B micro USB 3.0 port • Power port • LED indicator
Maximum Data Rate	<ul style="list-style-type: none"> • Up to 5Gbps
Special Features	<ul style="list-style-type: none"> • Compact form factor • Flexible USB 3.0 cable • Full power to connected devices
Power adapter	<ul style="list-style-type: none"> • Input: 100-240V, 50/60Hz • Output: 5V DC, 4A • Consumption: Max. 20 Watts
USB bus powered	<ul style="list-style-type: none"> • Output: 5V DC, 0.9A • Consumption: Max. 4.5 Watts
USB Charging	<ul style="list-style-type: none"> • Standard Mode • Max. 0.9A total for all USB ports • Fast Charge Mode (with optional power adapter) • Max. 1.5A per port for Battery Charging 1.2 compliant devices • Max. 2.4A per port for Smartphone/Tablet

Operating Temperature	• 0° - 40° C (32° - 104° F)
Operating Humidity	• Max. 90% non-condensing
Certifications	<ul style="list-style-type: none"> • CE • FCC
Dimensions	• 75 x 51 x 14.5mm (2.95 x 2.01 x 0.57 in.)
Weight	• 42g (1.48 oz.)
Warranty	• 2-year limited

PACKAGE CONTENTS

- TU3-H4
- USB 3.0 Cable (1m / 3 ft.)
- Quick Installation Guide
- Power adapter (5V DC, 4A)