


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0757595001](#)
Status: **Active**
Overview: SFP+ and SFP Interconnect Solutions
Description: Small Form-factor Pluggable (SFP) Stacked 2-by-2 Multi-Port Connector with Press-fit PC Tails, 80 Circuits, Lead-Free

Documents:

3D Model	Application Specification AS-76090-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-75714-001-001 (PDF)
Application Specification AS-75310-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-75310-001-001 (PDF)	

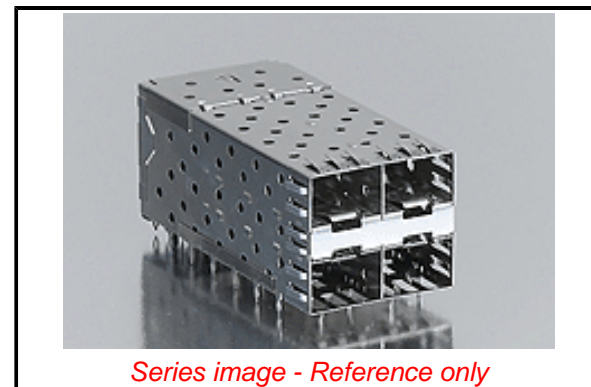

Series image - Reference only

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	I/O Connectors
Series	75759
Application	Module-to-Board
Component Type	Receptacle
Overview	SFP+ and SFP Interconnect Solutions
Product Name	SFP
Type	N/A
UPC	822350235440

Physical

Boot Color	N/A
Circuits (Loaded)	80
Circuits (maximum)	80
Color - Resin	Black
Durability (mating cycles max)	100
Flammability	94V-0
Gender	Female
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	43.982/g
Number of Rows	2
Orientation	Right Angle
PC Tail Length	2.07mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	2.36mm
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.80mm
Pitch - Termination Interface	0.80mm
Plating min - Mating	0.762µm
Plating min - Termination	0.762µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	4
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +85°C

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[75759](#) Series

Use With

[75951-0999](#) SFP Dust Plug

Termination Interface: Style Through Hole - Compliant Pin
Waterproof / Dustproof No

Electrical

Current - Maximum per Contact 0.5A
Shielded No
Voltage - Maximum 120V AC (RMS)/DC

Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Application Specification AS-75310-001, AS-75310-001-001, AS-76090-001-001
Packaging Specification PK-75714-001-001
Sales Drawing SD-75759-001

This document was generated on 09/13/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION