



Datasheet

ENGLISH


162-3012

# RS Pro AHD Bullet Camera (720P)



## Feature

- 1/3", 1.27 MP Sony Exmor CM OS
- 720P AHD Video Output
- AHD Transmission Max.300M (3C-2V)
- Colour : 0.1Lux, B/ : 0.05 Lux
- 3D-DNR, D-WDR, Sens-up
- Mega f=3.6 mm Fixed Lens
- Power requirement : DC12 V (±30%),  
Power source is not included

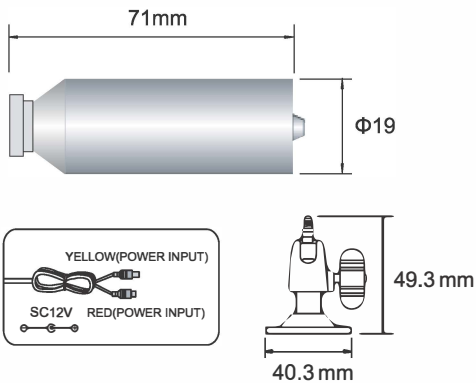

Specifications	NTSC / PAL
Image Device	1/3", 1.27 Megapixel Sony Exmor CMOS
Total Pixels	1312 (H) x 993 (V)
Active Pixels	1297 (H) x 977 (V)
Scanning System	Progressive
Resolution	AHD 720P
Video Output	AHD
S/N	More than 52 dB (AGC Off)
LENS	Mega f=3.6 mm Fixed lens
Electronic Shutter	NTSC : 1/30 ~ 1/50,000 sec (Auto) PAL : 1/25 ~ 1/50,000 sec (Auto)
Min. Illumination	Colour: 0.1 Lux / BW : 0.05 Lux
White Balance	ATW
Shutter Speed	AUTO
SENS-UP	AUTO(x6)
Day & Night	AUTO
DNR	3D-DNR
Power Input	DC+12 V ± 30%
Power consumption	100 mA
Operation Temperature	-10°C - +50°C
Storage Temperature	-20°C - +60°C
Weight	Approx 110 g included bracket
Housing	Aluminium
Dimension (mm)	Φ 19 × 71 mm