

## Bit fine-tooth ratchet 1/4" with push-out function

419B



Product no. 11131010  
GTIN 4018754286607  
Model 419B



**Label.** 1/4 Bit fine-tooth ratchet RSW.4.5° L.115mm

### Properties.

- reversible, with a push-out function
- 80 teeth
- with 2-component handle
- internal 1/4" hex drive with collar-thrust spring
- for 1/4" screwdriver bits
- for working in tight spaces, with a working angle of just 4.5°
- FOD-preventive due to screwless design
- DIN 3126 / ISO 1173 Form D 6.3

## Technologies and features.



### QuickRelease

The QuickRelease safety lock prevents unintentional loss of insert tools. These click securely into place, and are only released again at the push of a button for a quick tool change. In transducers: The QuickRelease safety lock helps you to quickly mount and change transducers. The transducers lock into the calibration system and only unlock again at the push of the buttons.



### Foreign Object Damage


STAHLWILLE protects against FOD (Foreign Object Damage). Our tool is ideal for safety-relevant sectors such as aviation, thanks to the screwless design.



### Fine-tooth ratchet mechanism

Our fine-tooth ratchets with 80 teeth re-engage after just 4.5° for maximum precision in confined spaces. 8 pairs of parallel teeth simultaneously ensure maximum load-bearing capacity and particularly smooth running, even at high torques.

### Technical drawing.

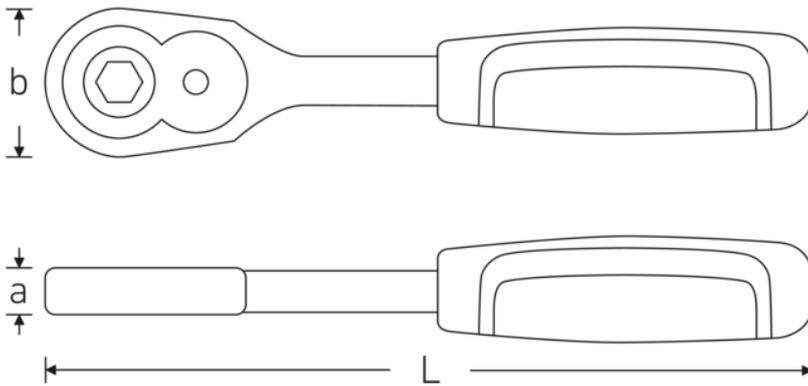

### Technical attributes.

<b>a</b>	16 mm
<b>Inner hex drive (inch)</b>	1/4
<b>Number of teeth</b>	80
<b>Working angle</b>	4.5 °
<b>Width mm (b)</b>	22 mm
<b>DIN</b>	DIN 3126 / ISO 1173 Form D 6,3
<b>Length mm (L)</b>	115 mm
<b>Alloy</b>	Chrome Alloy Steel

### Logistics data.

<b>Depth mm (IFS)</b>	115
<b>Width mm (IFS)</b>	22
<b>Height mm (IFS)</b>	18
<b>WEEE/ElektroG</b>	nicht ear-pflichtig
<b>Length (packaged, mm)</b>	120
<b>Width (packaged, mm)</b>	90
<b>Height (packaging, mm)</b>	20
<b>Volume (packaged, dm3)</b>	0.216 dm3
<b>Product no.</b>	11131010
<b>Weight (gross, kg)</b>	0,385
<b>Weight PAP (kg)</b>	0,000
<b>Weight PVC (kg)</b>	0,004
<b>GTIN</b>	4018754286607
<b>Country of origin AWR</b>	GERMANY
<b>Region of origin</b>	Nordrhein-Westfalen
<b>Customs tariff no.</b>	82042000
<b>Packing standard</b>	5
<b>Weight (g)</b>	76 g

## Variants.

Product no.	Model No. (ERP)	Description	GTIN
11131010	419B	1/4 Bit fine-tooth ratchet RSW.4.5° L.115mm	4018754286607

## GTIN.



## Accessories (for).



08310003  
Screwdriver bit



08130040  
Screwdriver bit



28011010  
Socket bit



08340020  
Screwdriver bit



08260003  
Screwdriver bit



08070123  
Screwdriver bit



08160030  
Screwdriver socket



08130045  
Screwdriver bit



28011013  
Socket bit



08340025  
Screwdriver bit



08260004  
Screwdriver bit



08070124  
Screwdriver bit



08160040  
Screwdriver socket



08131025  
Screwdriver bit



08330003  
Screwdriver bit



08340027  
Screwdriver bit



08260005  
Screwdriver bit



08070125  
Screwdriver bit



08010000  
Screwdriver bit



08330004  
Screwdriver bit



08340030  
Screwdriver bit



08260006  
Screwdriver bit



08070126  
Screwdriver bit



08010001  
Screwdriver bit



08330005  
Screwdriver bit



08340040  
Screwdriver bit



08260008  
Screwdriver bit



08070130  
Screwdriver bit



08260000  
Screwdriver bit



08010002  
Screwdriver bit



08330006  
Screwdriver bit



08260010  
Screwdriver bit



08070127  
Screwdriver bit



08010003  
Screwdriver bit



08330008  
Screwdriver bit



08260016  
Screwdriver bit



08070128  
Screwdriver bit



08050001  
Screwdriver bit



08162010  
Screwdriver bit



08090002  
Screwdriver bit



08260020  
Screwdriver bit



08070129  
Screwdriver bit



08250000  
Screwdriver bit



08050002  
Screwdriver bit



08162015  
Screwdriver bit



08090003  
Screwdriver bit



08130006  
Screwdriver bit



08260024  
Screwdriver bit



08300635  
Screwdriver bit



08250001  
Screwdriver bit



08050003  
Screwdriver bit



08162020  
Screwdriver bit



08090004  
Screwdriver bit



08130007  
Screwdriver bit



08161010  
5-star screwdriver bit



08300840  
Screwdriver bit



08250002  
Screwdriver bit



08320001  
Screwdriver bit



08162025  
Screwdriver bit



08090005  
Screwdriver bit



08130008  
Screwdriver bit



08161015  
5-star screwdriver bit



08301055  
Screwdriver bit



08250003  
Screwdriver bit



08320002  
Screwdriver bit



08162027  
Screwdriver bit



08090006  
Screwdriver bit



08130009  
Screwdriver bit



08161020  
5-star screwdriver bit



08301265  
Screwdriver bit



08250004  
Screwdriver bit



08320003  
Screwdriver bit



08162030  
Screwdriver bit



08090008  
Screwdriver bit



08130010  
Screwdriver bit



08161025  
5-star screwdriver bit



08301680  
Screwdriver bit



08250005  
Screwdriver bit



08162040  
Screwdriver bit



08200004  
Screwdriver bit



08130015  
Screwdriver bit



08161027  
5-star screwdriver bit



08250006  
Screwdriver bit



08160010  
Screwdriver socket



08200010  
Screwdriver bit



08130020  
Screwdriver bit



08161030  
5-star screwdriver bit



08230001  
Special socket bit



08160015  
Screwdriver socket



08200011  
Screwdriver bit



08130025  
Screwdriver bit



08161040  
5-star screwdriver bit



08070120  
Screwdriver bit



08160020  
Screwdriver socket



08310001  
Screwdriver bit



08130027  
Screwdriver bit



28011007  
Socket bit



08340010  
Screwdriver bit



08260001  
Screwdriver bit



08070121  
Screwdriver bit



08160025  
Screwdriver socket



08310002  
Screwdriver bit



08130030  
Screwdriver bit



28011008  
Socket bit



08340015  
Screwdriver bit



08260002  
Screwdriver bit



08070122  
Screwdriver bit



08160027  
Screwdriver socket

## Images.



**STAHLWILLE Eduard Wille GmbH**

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal