

Datasheet


Double open End Spanner 17x19mm

RS Stock number 495-3813



1. Material: Drop Forged Chrome Vanadium Steel (CR-V # 6140)
2. Finish: Flat Panel with Mirror Polish and Chrome Plated
3. Hardness: Heat Treated to HRC: 42° ~ 48°
4. Standard: Hardness Range, Torque Load Test, Gauges, Dimensions Meet ANSI - B107.9M

Dimensions (mm):

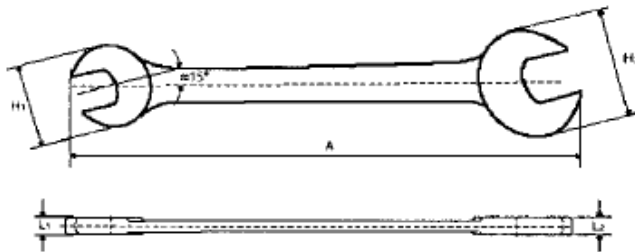

Sizes (MM)	Outside Dimension Small End (H ₁)		Thickness Small End (L ₁)		Outside Dimension Large End (H ₂)		Thickness Large End (L ₂)		Overall Length (A)	
	Dimension	Tolerance	Thickness	Tolerance	Dimension	Tolerance	Thickness	Tolerance	Length	Tolerance
6 x 7	14.50	+0.0, -1.8	4.70	+0.4, -1.2	16.50	+0.0, -1.8	4.70	+0.4, -1.2	126.0	+1.0, -1.5
8 x 9	18.00	+0.0, -1.8	4.90	+0.4, -1.2	20.00	+0.0, -1.8	4.90	+0.4, -1.2	135.0	+1.0, -1.5
8 x 10	18.00	+0.0, -1.8	4.90	+0.4, -1.2	20.00	+0.0, -1.8	4.90	+0.4, -1.2	135.0	+1.0, -1.5
10 x 11	21.00	+0.0, -1.8	5.50	+0.4, -1.2	23.50	+0.0, -1.8	5.50	+0.4, -1.2	146.0	+1.0, -1.5
12 x 13	27.00	+0.0, -1.8	6.60	+0.4, -1.2	29.70	+0.0, -1.8	6.60	+0.4, -1.2	165.0	+1.0, -1.5
14 x 15	29.70	+0.0, -1.8	7.10	+0.4, -1.2	34.00	+0.0, -1.8	7.10	+0.4, -1.2	185.0	+1.0, -1.5
16 x 17	34.00	+0.0, -1.8	7.50	+0.4, -1.2	37.00	+0.0, -1.8	7.50	+0.4, -1.2	185.0	+1.0, -1.5
17 x 19	37.00	+0.0, -1.8	8.30	+0.4, -1.2	40.00	+0.0, -1.8	8.30	+0.4, -1.2	227.0	+1.0, -1.5
18 x 19	37.00	+0.0, -1.8	8.30	+0.4, -1.2	40.00	+0.0, -1.8	8.30	+0.4, -1.2	227.0	+1.0, -1.5
20 x 22	43.50	+0.0, -1.8	9.00	+0.4, -1.2	46.00	+0.0, -1.8	9.00	+0.4, -1.2	255.0	+1.0, -1.5
21 x 23	43.50	+0.0, -1.8	9.00	+0.4, -1.2	46.00	+0.0, -1.8	9.00	+0.4, -1.2	255.0	+1.0, -1.5
22 x 24	50.00	+0.0, -1.8	10.00	+0.4, -1.2	52.00	+0.0, -1.8	10.00	+0.4, -1.2	293.0	+1.0, -1.5
24 x 26	50.00	+0.0, -1.8	10.00	+0.4, -1.2	52.00	+0.0, -1.8	10.00	+0.4, -1.2	293.0	+1.0, -1.5
24 x 27	50.00	+0.0, -1.8	10.00	+0.4, -1.2	52.00	+0.0, -1.8	10.00	+0.4, -1.2	293.0	+1.0, -1.5
30 x 32	58.00	+0.5, -0.5	12.00	+0.4, -0.4	64.50	+0.5, -0.5	12.00	+0.4, -0.4	369.0	+1.5, -1.5