


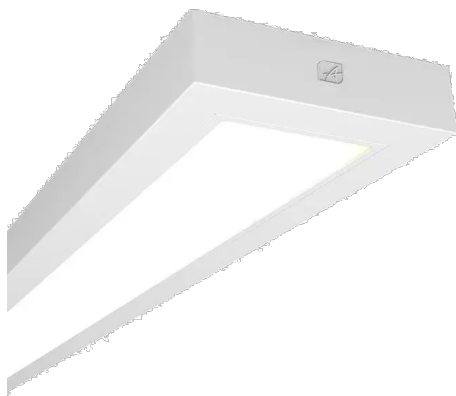

Application	Ancillary, Commercial, Education, Retail
Specification	Performance

Gemini

Gemini UGR<19 Linear 1500mm Self-Test Emergency

Code: AGEM5/1/SM3



PRODUCT FEATURES


- High-specification linear luminaire suitable for commercial, educational, and healthcare applications
- UGR<19 (unified glare rating) compliant luminaire assisting to eliminate glare for visual comfort
- Intelligent design with easy install base plate and a push-up, clip-in body design, ensuring a quick and easy installation
- Robust steel construction
- CCT selectable between 3000K, 4000K and 5000K and power selectable; offering a choice of outputs, in one luminaire
- Microprism diffuser for enhanced photometric performance
- Removable end cap covers provide convenient access for surface conduit wiring, making installation easier and more versatile
- Suitable for surface and suspension

GENERAL INFORMATION

Wattage	25W - 40W
Lumens Delivered	3300lm - 5800lm (4000K)
Lm/W	130lm/W - 150lm/W (4000K)
Beam Angle	90
CRI	80
CCT	3000/4000/5000K
Input	220-240V
Operating Temp	-20°C to 40°C
SDCM	3
UGR	19
Product Weight without Packaging	5.26 kg

TECHNICAL INFORMATION

Light Source	LED
Colour / Finish	White
Fire Rated	Yes
IP Rating	IP20
IK Rating	IK06
Class Protection	1
Internal / External	Internal
Surface / Recessed / Suspended	Surface, Suspended
Lumen Depreciation	L80 50,000h
Warranty (Years)	5
CE Mark	Yes
Height	64 mm

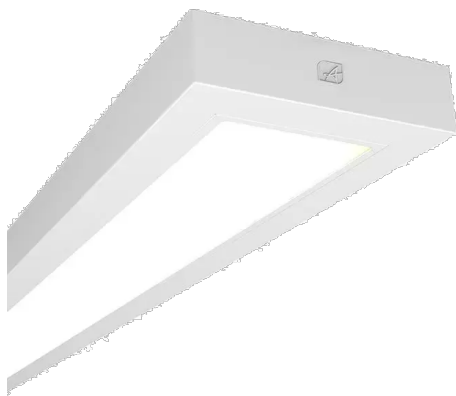

Application	Ancillary, Commercial, Education, Retail
Specification	Performance

Gemini

Gemini UGR<19 Linear 1500mm Self-Test Emergency

Code: AGEM5/1/SM3

