


WINSLOW ADAPTICs

W3437G TRANSISTOR SOCKET TO5 STYLE, 3 PIN, 0.2" PCD

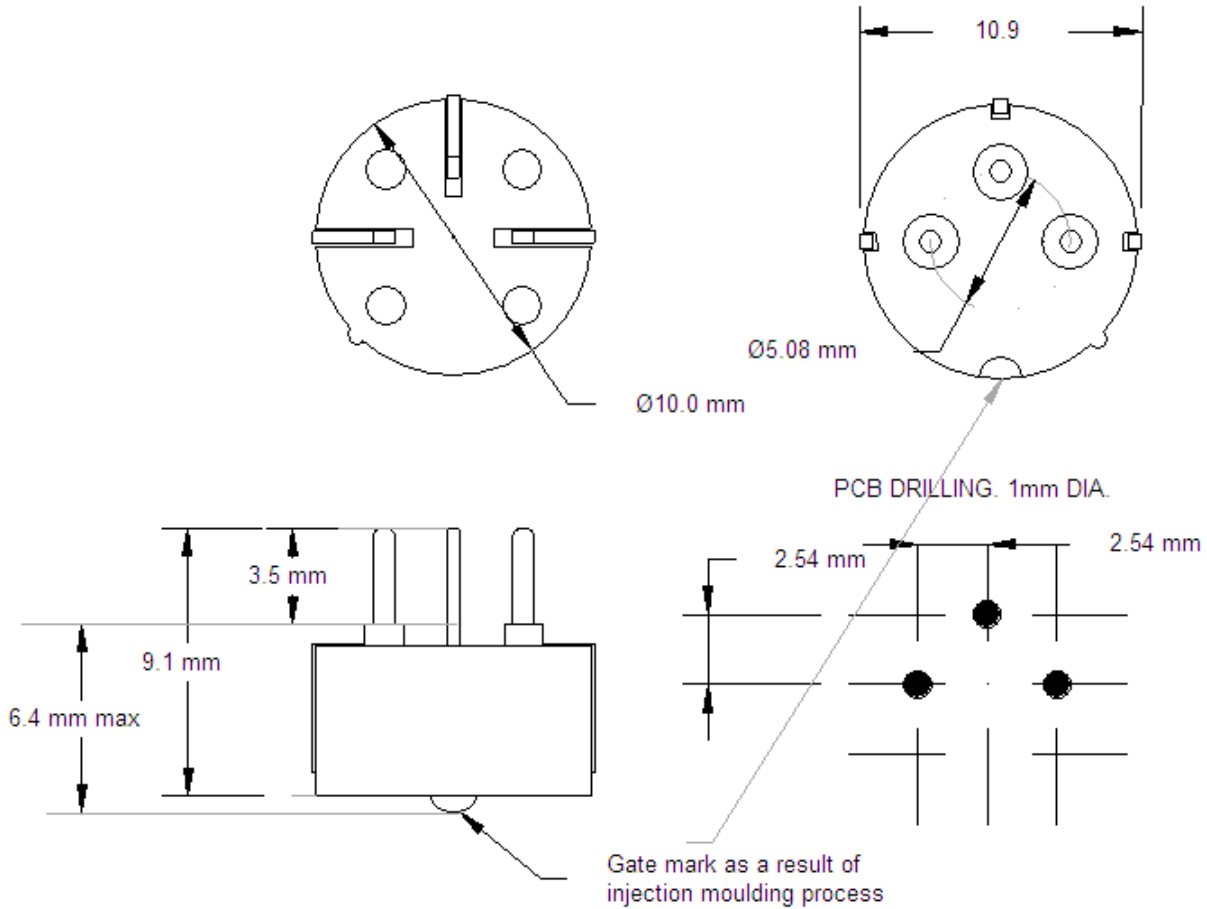


INSULATOR:	30% GLASS FILLED POLYESTER RATED UL94V-0
CONTACT:	NICKEL GOLD PLATED PHOSPHOR BRONZE.
INSERTION FORCE:	200g
WITHDRAWAL FORCE:	150g
ACCEPTABLE PIN SIZE:	0.50mm
TEMPERATURE RANGE:	-65C TO +150C




sales@winslowadaptics.com

DIP Support products from Winslow Adaptics

www.winslowadaptics.com

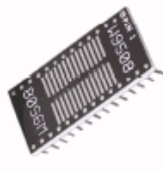

Package

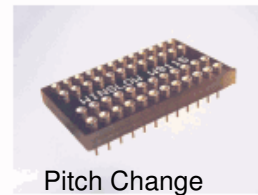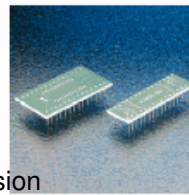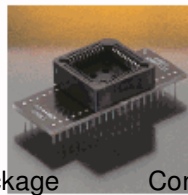

Also available from Winslow Adaptics are cost effective, time saving solutions to test, obsolescence, supply problems and upgrades. OEMs can upgrade equipment with custom Adaptics utilising additional logic, often saving considerable cost and time on re-design. If lead-time becomes an issue contact us for a suitable package converter. We specialise in conversion of all package lead-frames.