

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

504193-0500

Status:


Active

Overview:

Micro-Lock™ Connectors

Description:

Micro-Lock™ 1.25mm Pitch Single-Row Crimp Housing, White, 5 Circuits

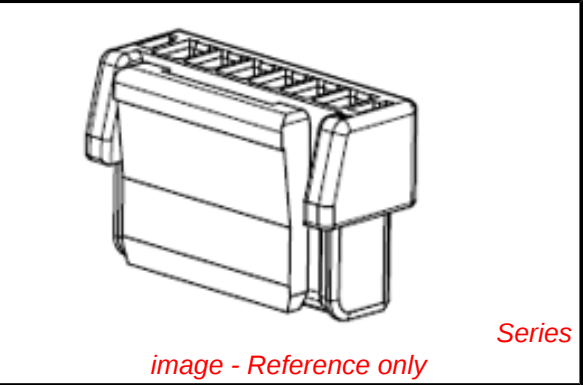

Documents:	
3D Model	Application Specification AS-504193-002 (PDF)
Drawing (PDF)	Packaging Specification SPK-504193-001 (PDF)
Product Specification PS-504193-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-504193-001 (PDF)	

General	
Product Family	Crimp Housings
Series	504193
Application	Wire-to-Board
Overview	Micro-Lock™ Connectors
Product Name	Micro-Lock™
UPC	887191165639
Physical	
Circuits (maximum)	5
Color - Resin	White
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	108.956/mg
Number of Rows	1
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-25°C to +85°C
Electrical	
Current - Maximum per Contact	1.5A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-504193-001, AS-504193-002
Packaging Specification	SPK-504193-001
Product Specification	PS-504193-001, RPS-504193-001, RPS-504193-002, RPS-504193-003
Sales Drawing	SD-504193-001

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

504193Series

Mates With

504194 Micro-Lock™ 1.25mm Pitch Vertical Header, 504195 Micro-Lock™ 1.25mm Pitch Right Angle Header

Use With

Micro-Lock™ Wire-to-Board Crimp Terminal 504185-1000

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION