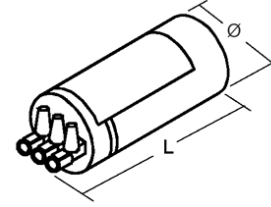


**Timed Ignitor 220/240V ±10% 50/60Hz**
**Ignitor Code: PCX400255**
**Electrical Data (Ignitor)**

Wattage (W)	35-450
Timed	Y
Ignitor Type	Superimposed
Max Lamp Current (A)	5
Pulse Magnitude (kV)	3.5-4.5
Max. Lead Capacitance (pf)	100
Max Case Temp (°C)	105
Internal Temp (°C)	30

**Physical Data (Ignitor)**


Dimensions (mm)	Ø	L	
	40	75	
Fixing	M8x10		
Weight (kg)	0.18		

**Notes:**

Data is based upon tests performed by Venture Lighting in a controlled environment and is representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.