

C58BC-W1,6 2C

Workbench, 1.6 m long, with wood worktop and 2 drawers

Main features:



- Worktop (1,600x750 mm) made from multi-ply wood, 38 mm thick
- 2 drawers (367x588 mm) with ball bearing slides:
1 drawer 70 mm high
1 drawer 140 mm high.
- Drawer bases protected by foamed rubber mats
- Each drawer can accommodate up to 4 EVA foam or ABS thermoformed trays
- Front centralized lock
- Steel frame with 4 supporting legs
- Holes for a vice (1599F/150 - 1599GI/150, to be ordered separately)
- Lower half-shelf for objects, 1,288x335 mm; thickness: 40 mm
- Can be fixed to floor
- Static load capacity: 1,000 kg, evenly distributed

Following accessories can be added:

- Perforated side panel C58PFL
- Anti-fall edge, 1,600 mm, C58BAC 1.6

 82 kg

1.600x750x904 mm

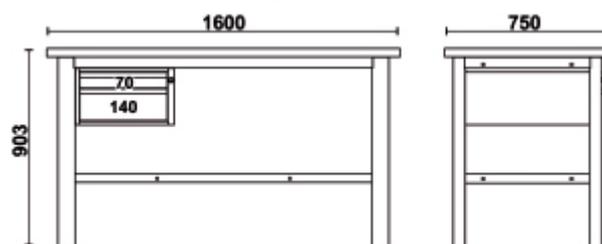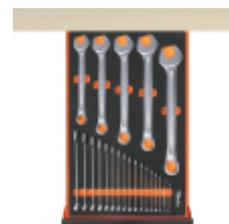

	art.		
058000611	C58BC-W1,6 2C/O		Orange
058000613	C58BC-W1,6 2C/A		RAL 7016