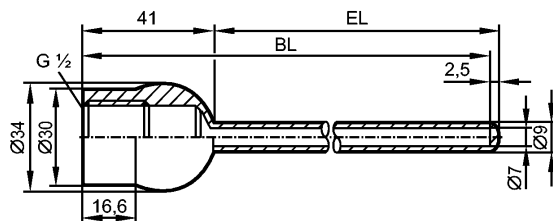


**E37431**

THERMOWELL,D6/WELD-IN/G1/2 conical/L=150

**Accessories**

**EC 1935/2004 FDA**
**Product characteristics**

Welding thermowell for temperature sensors

Ø 6 mm

**Environment**

Pressure rating [bar] 300

**Mechanical data**

Process connection	ball Ø 34 mm
for units with process connection	G½ with sealing cone
Installation length EL [mm]	149
Bore Length BL [mm]	187
Design	for temperature sensors with installation length EL = 150 mm
Housing materials	stainless steel 316L / 1.4404
Surface characteristics Ra / Rz of the wetted part(s)	≤ 0.6 / -
Weight [kg]	0.18

**Remarks**

Pack quantity [piece] 1