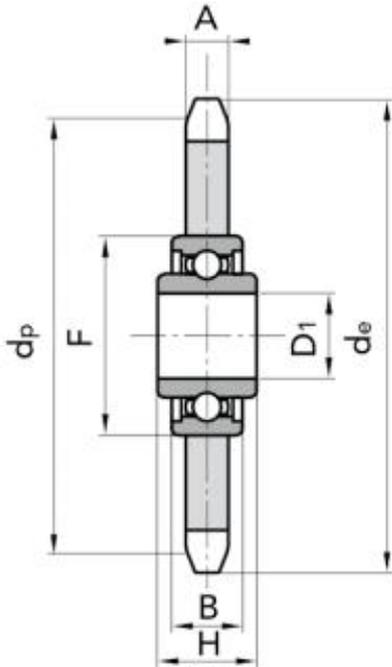


**30025012**

With economic bearing - Idler sprocket

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	12
Pitch (P) mm	1" x 17.02
de (DE) mm	109
dp (DP) mm	98.14
Part number (CODE)	30025012
A (A) mm	16.2
D1 (D1) mm	20
F (F) mm	47
B (B) mm	14
H (H) mm	17.7
Weight (WEIGHT) kg	0.72
Material (MAT)	STEEL C45