


Item no.: 289-431  
 Product description: Interface module with female connector 64 pole for male connector with solder contact type c for connection plugs per DIN 41612 mating connection vertical

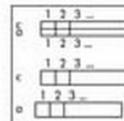

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Operating voltage	AC / DC 125 V
Nominal current	1 A
Connector contact	Cu-alloy, with gold
Contact resistance	<= 20 mOhm
Performance level	2 / 400 mating cycles
Nominal voltage acc. to VDE 0110/1.89	50 V / 0,8 kV / 2
Cross section [mm²]	0.08 - 2.5 mm²
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP®CONNECTION
Weight	109.9 g
Height	21 mm
Height	0.827 in
Width	187 mm
Width	7.362 in
Depth	63.5 mm
Depth	2.5 in
Strip length from	5 mm

Strip length to	6 mm
Strip length	0.22 in
Mounting	TS 35

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected