




# CRIMP TOOLS

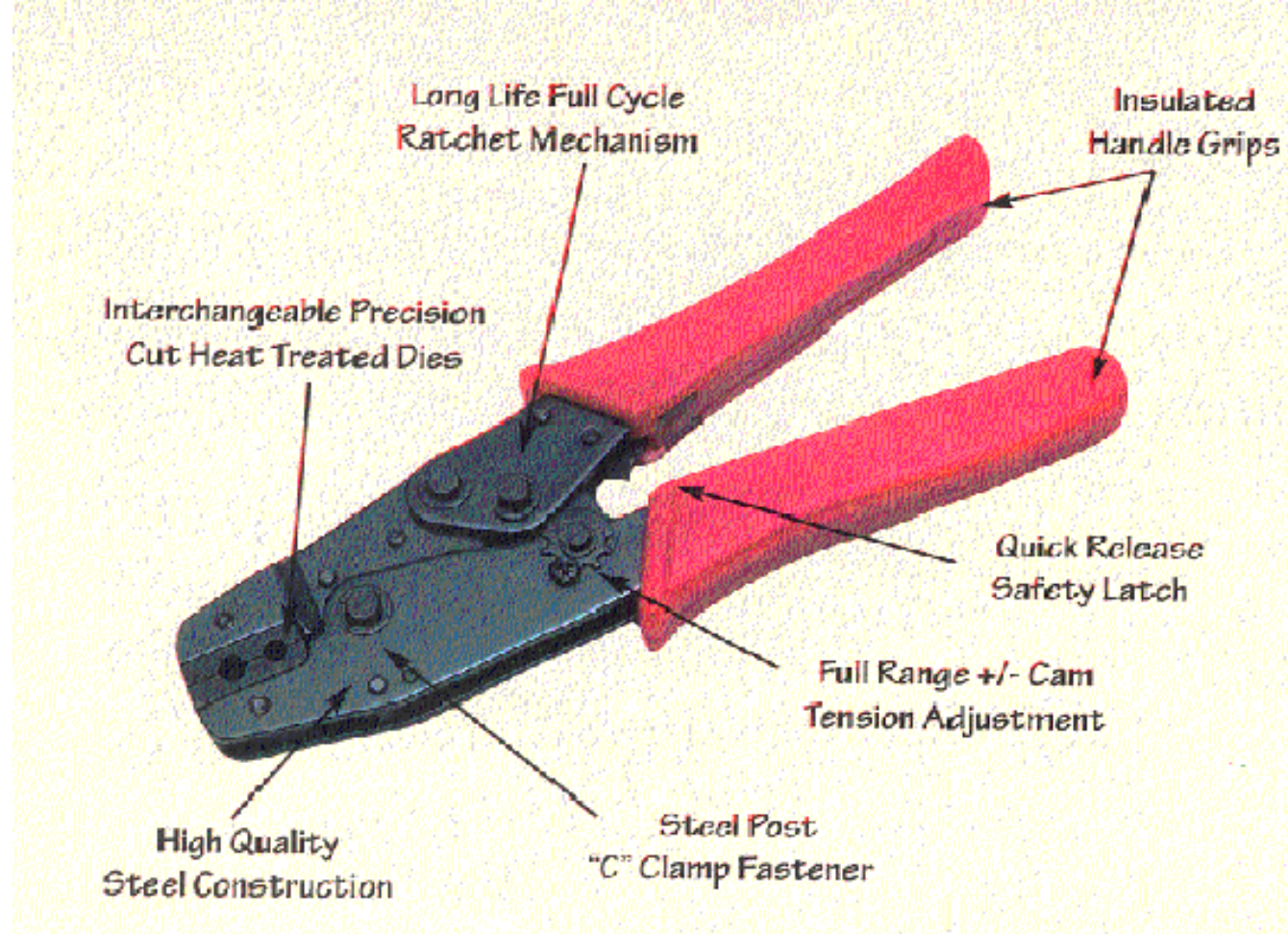

## Features:

- Sure Grip Handles
- Replaceable Dies
- Performs both electrical and mechanical crimp
- High quality steel

| <b>TOOL STOCK #</b> | <b>CABLE SIZE</b>                                   | <b>DESCRIPTION</b>   | <b>SIZE</b>            | <b>DIE STOCK #</b> |
|---------------------|---|--|------------------------|--------------------|
| <b>24-8856P</b>     | RG6, 8, 59, 62                                      | 3 pc. BNC & TNC with standard rings                                      | .390, .275, .065       | <b>99-8856</b>     |
| <b>24-8857P</b>     | RG58U, 58AU, 174, 139, 185, 188, 316                | 3 pc. BNC & TNC with standard rings                                      | .235, .128, .065, .042 | <b>99-8857</b>     |
| <b>24-8858P</b>     | RG58, 58AU, 59 Teflon, 62 Teflon                    | 2 & 3 pc. BNC & TNC and 1/2" ring F conn.                                | .325, .210, .065       | <b>99-8858</b>     |
| <b>24-8859P</b>     | RG59, 62, Belden 8281                               | 2 & 3 pc. BNC & TNC with standard and dual crimp rings                   | .325, .258, .065       | <b>99-8859</b>     |
| <b>24-8789P</b>     | RG58, 59, 62, 58TFE, 59TFE, 62TFE                   | 2 & 3 pc. BNC & TNC with standard crimp rings by AMP, Amphenol, Kings    | .257, .210, .060       | <b>99-8789</b>     |
| <b>24-8786P</b>     | RG6, 58   | 2 pc. BNC & TNC with standard rings by Amphenol, Kings                   | .320, .210, .185       | <b>99-8786</b>     |
| <b>24-9858P</b>     | RG58, 59TFE   | 2 pc. BNC & TNC  | .320, .211             | <b>99-9858</b>     |
| <b>24-9859P</b>     | RG59, 62  | 2 pc. BNC & TNC  | .320, .250             | <b>99-9859</b>     |
| <b>24-9958P</b>     | RG58, 58TFE, 59TFE, 141, 142, 223, 400, 303, 55     | 3 pc. BNC & TNC Mini UHF   | .213, .060             | <b>99-9958</b>     |
| <b>24-9959P</b>     | RG59, 62, 450 Proflex, 8X                           | 3 pc. BNC & TNC Mini UHF   | .255, .060             | <b>99-9959</b>     |
| <b>24-9912P</b>     | RG122, 180, 34M, 195, 8218, 174, 188, 179, 187, 316 | 3 pc. BNC & TNC  | .184, .060             | <b>99-9912</b>     |
| <b>24-8644P</b>     | Open barrel crimper V.35 contacts                   | 10-22 ga. AWG non-insulated open barrel conn., D-sub mini pins & sockets |                        | <b>99-8644</b>     |