


## Features

- **High-Capacity Design** – Holds up to 48 safety padlocks, enabling simultaneous lockout operations for large teams or high-risk areas.
- **Shadow Board Visual System** – Features shadow outlines to instantly indicate missing or in-use devices, improving visibility, accountability, and operational safety.
- **Heavy-Duty Construction** – Built from 4 mm thick ACP board with a red/white high-visibility striped design for rugged, industrial use.
- **Point-of-Use Efficiency** – Ideal for installation near machinery, keeping essential lockout tools within reach to reduce response time and downtime.
- **Organised Storage** – Pre-fitted with durable nylon hooks to ensure systematic, tidy storage of padlocks and accessories.

## RS PRO Shadow Lockout Station for 48 Locks - With Goods

RS Stock No.: 0642802

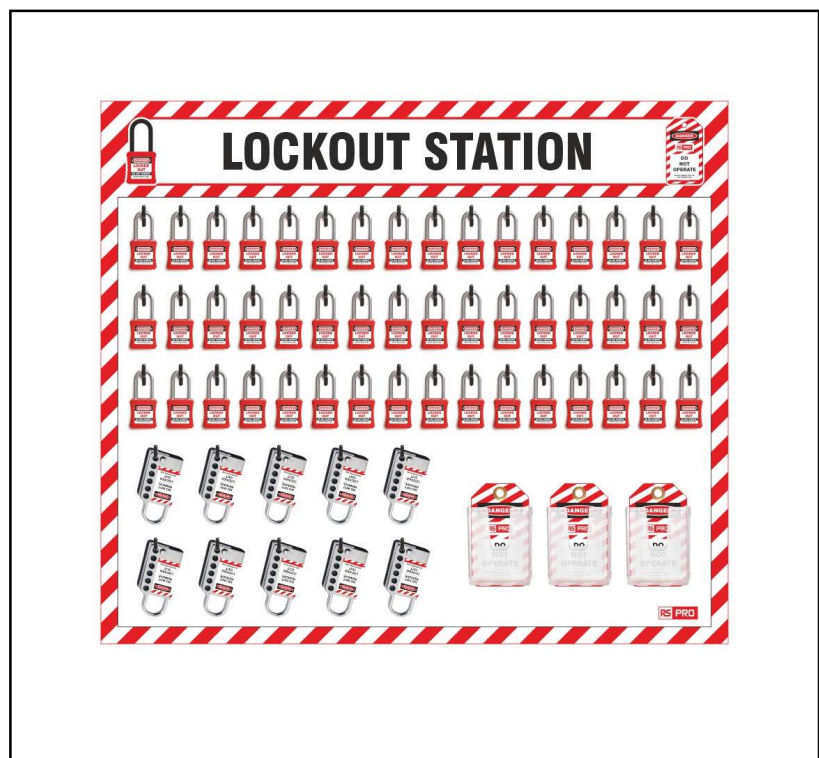

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

- *The Shadow Lockout Station is a complete, fully-equipped LOTO (Lockout Tagout) board designed for localised lockout operations.*
- *Ideal for high-risk work areas, this board supports the safe and organised deployment of up to 48 lockout safety padlocks, enabling rapid access to essential devices while clearly displaying their availability through shadow outlines.*
- *The shadow board format enhances operational safety by acting as a visual status indicator—making it instantly clear which devices are currently in use or missing.*
- *Can hold and manage up to 48 padlocks for simultaneous energy isolation.*
- *Comes with pre-fitted durable nylon hooks for organised and accessible storage.*
- *Ideal for Point-of-Use Lockout: Designed for use near machinery to keep lockout tools within reach.*
- *This system helps maintain compliance with safety protocols while reducing equipment downtime and improving workplace control.*

## General Specifications

|          |                                     |
|----------|-------------------------------------|
| Type     | Shadow Lockout Station              |
| Material | 4mm Aluminium Composite Panel (ACP) |
| Colour   | Red/ White                          |
| Package  | Box with corrugated fittings        |

## Mechanical Specifications

|                    |                      |
|--------------------|----------------------|
| Dimensions (W X H) | 940mm X 813mm X 40mm |
| Width              | 940mm                |
| Height             | 813mm                |
| Board thickness    | 40mm                 |
| Weight             | 10.3 Kgs             |

## Operation Environment Specifications

|                       |                |
|-----------------------|----------------|
| Withstand temperature | -20°C to +80°C |
|-----------------------|----------------|

## Accessories

| Item Name              | Item Description                                                              | Quantity |
|------------------------|-------------------------------------------------------------------------------|----------|
| Lockout Padlock        | Premier Lockout Safety Padlock with 46 mm Steel Shackle - Key Different - Red | 48       |
| Hasp                   | Stainless Steel Hasp - 25 mm                                                  | 10       |
| Lockout Tags           | Danger "Do Not Operate" Lockout Tags                                          | 30       |
| Shadow Lockout Station | Shadow Lockout Station for 48 Locks                                           | 1        |