

BUMPER

Features

- **Sleek Design:** Black finish blends into any environment.
- **Abrasion Resistant:** Withstands repetitive impact and wear.
- **Durable Protection:** Safeguards furniture, doors, and property in residential and commercial spaces.


Cylindrical Bumper 33D x 22H

SKU.: 0734081



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

BUMPER

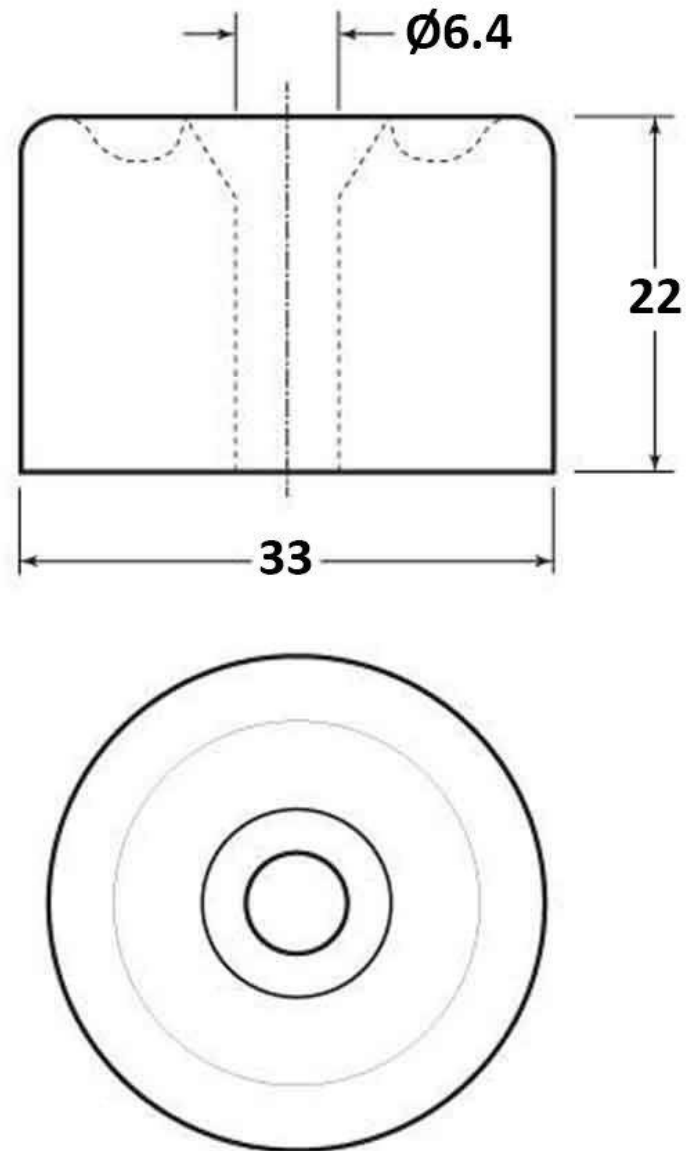

Bumper Dimensions

Diameter (mm)	33
Height (mm)	22

BUMPER

Product Description

Cylindrical Rubber Bumpers are manufactured from a premium blend of NR and SBR rubber, offering outstanding abrasion resistance, tear strength, and impact resilience for long-lasting performance in diverse environments. Their sleek black design ensures they blend seamlessly into any setting while delivering reliable functionality. These bumpers are ideal for use as door stops to prevent doors from swinging open too far, vibration dampers to reduce noise and enhance comfort, spacers to maintain proper alignment in installations, and protective buffers to safeguard furniture, walls, and property from repeated impact. Perfect for kitchens, offices, warehouses, and high-traffic areas, they provide a versatile solution that combines durability, safety, and aesthetics.

General Specifications

Material	NR/SBR
Colour	Black

Mechanical Specifications

Weight	0.024KG
Tensile Strength	4Mpa
Elongation	200%
Hardness	75ShA

Operation Environment Specifications

Maximum Temperature	70°C
Minimum Temperature	-15°C