


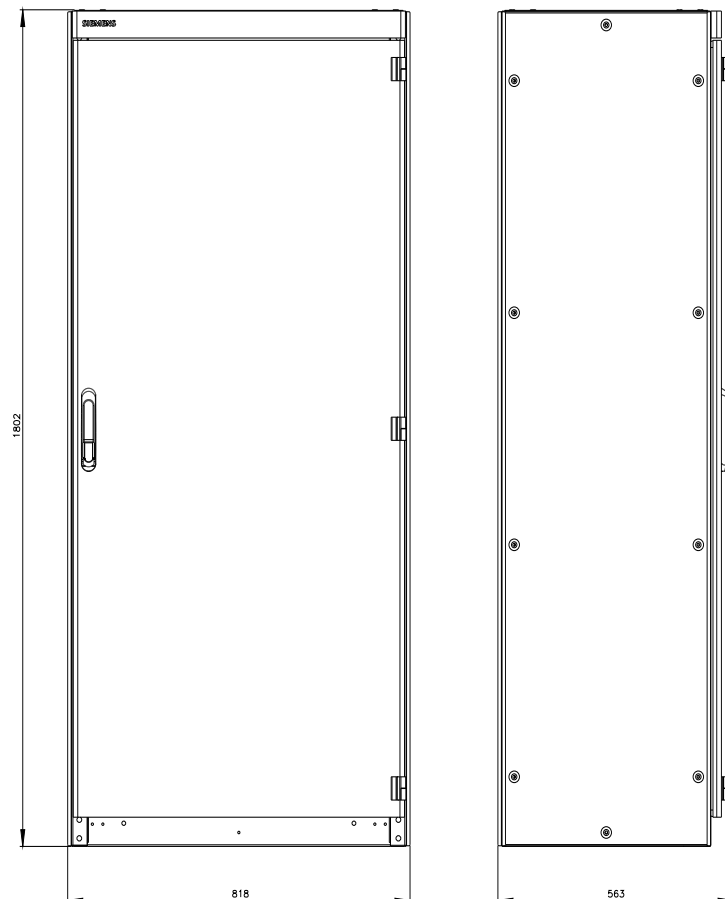

SIVACON, Control panel Empty enclosure, according to IEC 62208, IP40, H: 1800 mm, W: 800 mm, T: 500 mm

Model	
product brand name	SIVACON
product designation	Empty control cabinet enclosure
design of the product	according to IEC 62208
design of the surface	Powder-coated
design of the product EMC version	No
Protection class	
protection class IP	IP40
operating resource protection class	Safety class 1
Suitability	
suitability for installation for metric dimensions	Yes
suitability for integration surface-mounted installation	No
suitability for integration flush mounting	No
suitability for use for outside use	No
Appearance	
RAL color number	RAL 7035
color	light grey
Product details	
product component	
• ventilation door	No
• mounting plate	Yes
• rear door	No
• viewing door	No
• height-adjustable mounting plate	Yes
product feature of the enclosure housing can be lined up	No
Number	
number of locking devices	0
number of doors	1
Mechanical Design	
height	1 800 mm
width	800 mm
depth	500 mm
fastening method	
• 19-inch installation	No
• floor mounting	Yes
• wall mounting	No
material	steel
Approvals Certificates	
General Product Approval	

EMV[KC](#)**Further information****Information on the packaging**<https://support.industry.siemens.com/cs/ww/en/view/109813875>**Information- and Downloadcenter (Catalogs, Brochures,...)**<http://www.siemens.com/lowvoltage/catalogs>**Industry Mall (Online ordering system)**<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1885-3BS4>**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**<https://support.industry.siemens.com/cs/ww/en/ps/8MF1885-3BS4>**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1885-3BS4**CAX-Online-Generator**<http://www.siemens.com/cax>**Tender specifications**<http://www.siemens.com/specifications>

last modified:

5/26/2025

