


## KB435 EQ Rechargeable Multi-Device Compact Keyboard

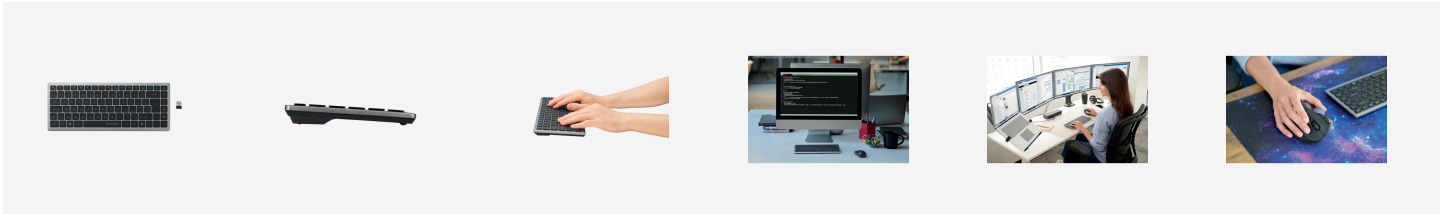

Ideal for professionals seeking peak productivity while working remotely, the KB435 EQ Rechargeable Multi-Device Compact Keyboard features quiet and responsive scissor-switch keys for a premium typing experience. It supports seamless wireless switching between four devices via 3 x Bluetooth® 5.4 connections and 1 x 2.4GHz USB-A receiver. Customise workflows with 15 programmable keys, a Copilot AI key\* and Function Lock. The rechargeable 500mAh battery lasts up to 4 months.\*\* LED indicators for Caps Lock and battery life keep you informed. The plastic used in the outer case of this keyboard is made with 39% post-consumer recycled (PCR) content and is shipped in FSC® certified packaging. Windows, macOS and ChromeOS compatible. Supported by optional Kensington Konnect™ software for customisation features. Includes a 3-year limited warranty. \* Windows only. \*\* Battery life may vary based on usage.



## Attributes

- Scissor-switch keys provide a quiet and responsive feel, help reduce fatigue and support accurate typing.
- Easy to carry, the compact design is an ideal choice for remote workers who work on-the-move.
- 15 programmable keys, a dedicated AI Copilot key\* and Function Lock for seamless multitasking. \* Windows only.
- Connect up to 4 devices: 3 via Bluetooth® 5.4 and 1 via 2.4GHz USB-A receiver, featuring 128-bit AES encryption and a 10m range.
- Supports up to 4 months of productivity with a single charge.\* \* Battery life may vary based on usage.
- Status indicators for Caps Lock, battery life and Bluetooth® pairing.
- The plastic in the outer case of this keyboard is made with 39% post-consumer recycled (PCR) content\* and it is shipped in FSC® certified packaging. \* Excludes PCB assembly, keycaps, rechargeable battery, 2.4GHz dongle and charging cable.
- Compatible with Windows, macOS and ChromeOS.\* No drivers or downloads needed. \* Copilot key works with Windows only.
- 3-Year limited warranty.

## Specifications

Number	K75409UK
Colour	-----
Dimensions (W x H x D)	125 x 20 x 317 mm
Weight	430 g
Pallet quantity	375
EAN code	5028252658911