


Datasheet

Stock No: 522-440

RS Pro SY Control Cable, 7 Core

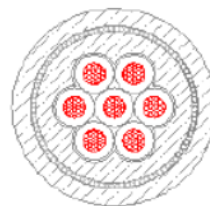

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω /Km) :

<21.1

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :

>500

Current Rating : 10 A

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):300

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): 0.20±0.008 x 32

Insulation: PVC

Insulation Dia. (mm): 2.52±0.1 x 7C

Filler : Chalk

Jacket 1: PVC

Outer Dia. (mm): 8.45±0.2

Braid Shield: Galvanised Steel

Conductor Dia. (mm): 0.24

Conductor Qty: 24 x 4

Jacket: Trans PVC

Outer Dia. (mm): 11.53±0.25

Colour:

The colour of the insulation: Black x 6 ,
Yellow/Green

The jacket colour: Transparent

Marking(3times/m):

RS 522440 SY/NR 7 Core x 1.0mm²