


manifold rail

VABM-L1-18W-G38-12-G

Part number: 8004920

FESTO

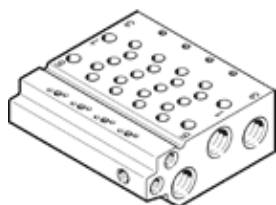

Data sheet

Feature	Value
Grid dimension	19 mm
Assembly position	Any
Max. number of valve positions	12
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Storage temperature	-20 ... 60 °C
Authorisation	c CSA us (OL) c UL us - Recognized (OL)
Product weight	2,785 g
Auxiliary pilot air port 12/14	G1/8
Pilot exhaust port 82/84	G1/8
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 4	G1/4
Pneumatic connection, port 5	G3/8
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy