

Features

- Accuracy of 0.001 in
- Not battery operated
- Imperial
- Measurement range of 0 in to 1 in
- External micrometer type
- Resolution of 0.001 in
- Includes case and adjustment tool

RS PRO External Micrometre, Range 0 in to 1 in

RS Stock No.: 725-5709



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO External Micrometre, Range 0 in to 1 in

Need a tool that will quickly and accurately measure the dimensions of small components? Thanks to its resolution of 0.0001 in, this external micrometre from RS PRO is ideal for precision engineering work. As its measuring faces are made from highly durable carbide, the faces won't chip and cause inaccurate readings.

The easy-to-use thimble on the micrometre features a knurled surface that provides excellent grip with or without gloves. There's a ratchet stop at the thimble's end to guarantee repeatable measures, which saves time when you need to measure multiple objects of the same size.

As part of the RS PRO range, this product has been tested by engineers for quality and reliability. You'll commonly find this type of micrometre used in manufacturing operations as a quality control instrument.

General Specifications


Accuracy	±0.001 in
Product Type	Micrometre
Resolution	0.001 in
Imperial/Metric	Imperial
Battery Operated	No
Micrometre Type	External
Standards/Approvals	No

Approvals

Declarations	REACH DoC
--------------	-----------

Feature:

- Carbide measuring faces.
- Painted frame.

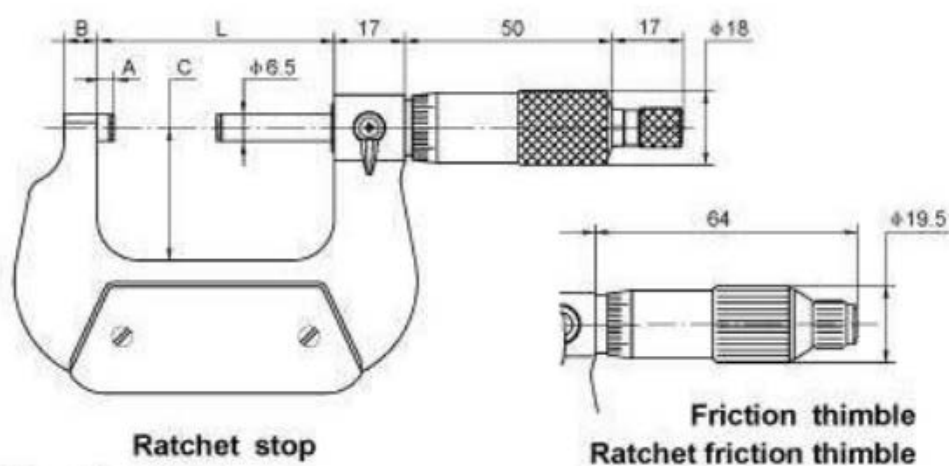

Dimensions

Range		A	B	C	L
Metric	Inch				
0-25mm	0-1"	3.0mm	8mm	24mm	32mm
25-50mm	1-2"	3.0mm	8mm	32mm	57mm
50-75mm	2-3"	3.0mm	8mm	45mm	82mm
75-100mm	3-4"	3.0mm	8mm	57mm	107mm
100-125mm	4-5"	3.0mm	8mm	70mm	133mm
125-150mm	5-6"	3.0mm	8mm	82mm	158mm
150-175mm	6-7"	5.5mm	8mm	95mm	183mm
175-200mm	7-8"	5.5mm	8mm	107mm	209mm