

LYNX CF-L18W/BL368 TC

Item No: 0025722

SYLVANIA


SpecialLITE®



These BL368 tubes emit an upgraded highly concentrated radiation with peak around 368nm. Flying insect - eye sensitivity is generally at or near this frequency 100% improvement in effectiveness (at 368nm) Depreciation of UV-A output over time is significantly reduced (80% at 5000hrs of original 100 hour output)

Technical Assets

Dimensions (mm)

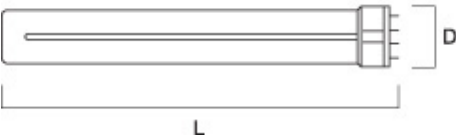

Photometrics

General data

Product name	LYNX CF-L18W/BL368 TC
Technology	Fluorescent
Lamp shape	U shape
Cap/Base	2G11
Lamp finish	Frosted/Coated
Fixture rating	Enclosed
General application	SPG
ETIM Class	EC002962
Warranty	2 years

Optical data

Light colour	BL368 Blacklight
Photobiological Risk Group	RG0

Electrical data

Supply current (A)	0.1
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Dimmable	No
Inrush Current (A)	15
Inrush Duration (µs)	200
Nominal Frequency (Hz)	50/60Hz

Physical data

Nominal Product Height (mm)	215
Nominal Product Diameter (mm)	44
Weight (kg)	0.058

LYNX CF-L18W/BL368 TC

Item No: 0025722



Packaging

Product EAN number	5410288257228
Packaging single length / height (cm)	24.53
Packaging single width (cm)	4.63
Packaging single depth (cm)	2.77
DUN14 (inner)	15410288257225
Units per outer package	10
Packaging outer length / height (cm)	26.2
Packaging outer width (cm)	14.0
Packaging outer depth (cm)	9.8

Safety data

Breakage cleaning instructions	Applicable
Special purpose lamp	Yes
Intended purpose	Flykilling - Insect attraction
Suitable for household illumination	No