



Brand of NTN corporation


Technical data

BBE30AUU

Standard ball bushings closed



VISUAL (S)

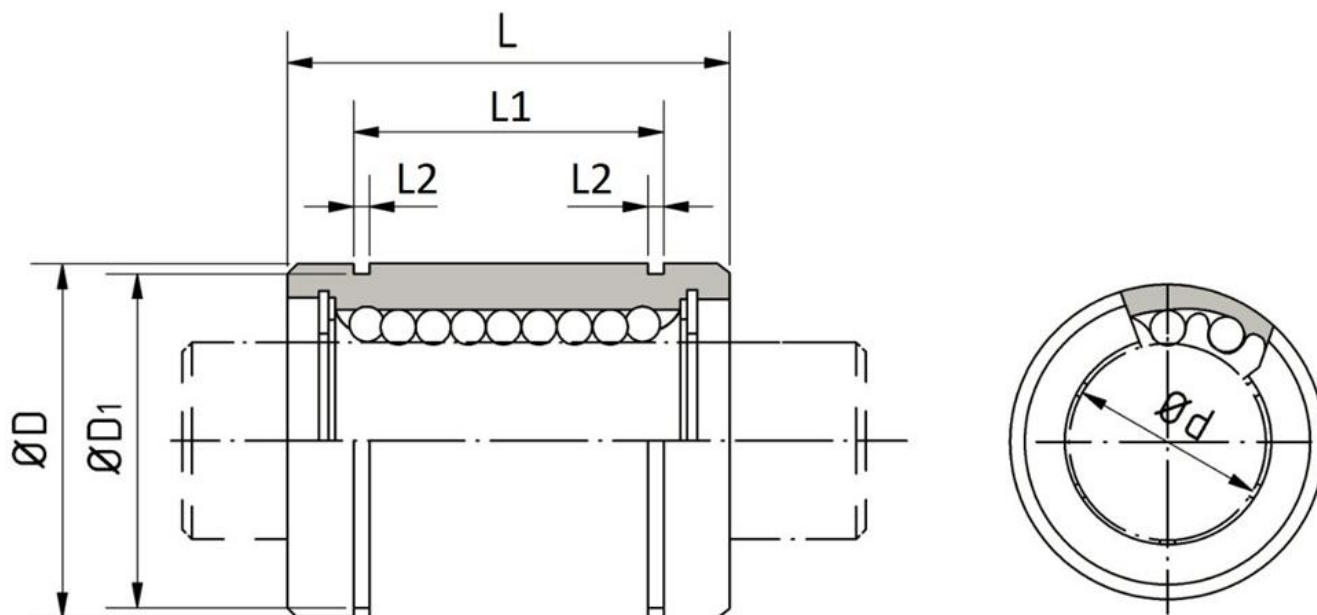

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	RSt34-2
Initial greasing	Non/No
d - Internal diameter	30 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter tolerance	0,011/-0,001
D - External diameter	47 mm
D - External diameter tolerance	0/-0,011
L - Length	68 mm
L - Length tolerance	0/-0,3
L1	52,1 mm
L1 tolerance	0/-0,3
D1 - Diameter	44,5 mm
L2	1,85 mm
Number of ball rows	6
Mass	0,36 kg

PRODUCT PERFORMANCE

Cmin	1,584 kN
Cmax	2,028 kN
C0min	2,47 kN
C0max	3,162 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	110 °C

ESHOPDONOTDISPLAY

Reference	BBE30AUU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

