

## Features

- Made of die-cast zinc
- Panel to tongue depth of 20 mm
- Key unlocking method

# RS PRO Chrome Die Cast Cabinet Lock, 20 mm Panel to Tongue, 19.5 x 16.5 mm

RS Stock No: 192-9654



RS PRO Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Install an RS PRO cabinet lock to keep your valuables safe. Locks are keyed alike. This type of lock is used in businesses, factories and at home.


It's made of die-cast zinc, which has good resistance to corrosion and means you can install it outdoors. It can resist repeated use and won't easily break if yanked too, as the zinc material is tough. It comes fully assembled, so it's ready to fit to a filing cabinet or drawer. This makes installation easy and saves you time.

The handle requires a 90-degree turn to operate, which prevents accidental openings and helps to avoid contents falling out. The IP54 (Ingress Protection) rating means it's able to resist dust and splashes of water too.

General Specifications

Lock Type	Key
Unlock Method	Key
Panel To Tongue Depth	20mm
Panel Cut Out	19.5 x 16.5mm
Material	Die Cast
Keyed Alike	Yes
Finish	Zinc
Colour	Chrome
IP Rating	IP54

Camlocks

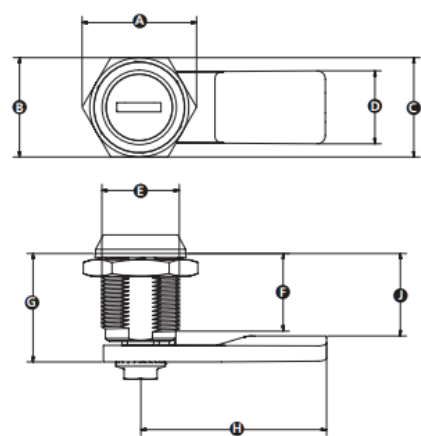

Part no.	A	B	C	D	E	F	G	H	I	J	Key type
1929654	28	22	24	18	19	18	26	45	-	20	With key