


# Blue Elastic Rubber Trolley Wheel 125mm treadguards, 200kg

Elastic Rubber-tyred wheel

PRODUCT

Article number

571-411-125R12PF

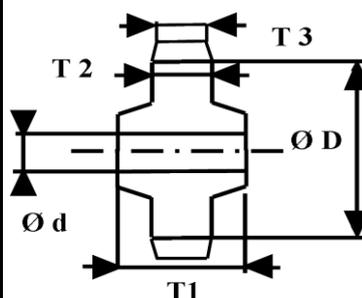

## Product Details

Wheel Rim : very thick black polyamide.

Tyre : solid, black bonded elastic rubber tyre.

Hub : symmetrical, roller bearing.

Delivered fitted with a M8 demountable axle and zinc-plated steel threadguards (M8x60 bolt).

## Specifications

Wheel Diameter - ØD ± 1%	125 mm
Hub Type	Roller bearing
Hub Length T1	45 mm ±1
Width of Tread T2	32 mm ±1
Width of Tread-on floor T3	30 mm ±1
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	200 Kg
Temperature	-20 / +60 °C
Weight	0,4 kg

TECHNICAL DATA

## Applications :

Sensitive materials handling on uneven surfaces.

Resilient with a low starting effort.

Does not leave scratches or other marks on surfaces.

Quiet in use and high wear resistance.

Reduces shock and vibration.

Suitable for industrial floors and also interior floors.