


KCL SIVOCEM® 759

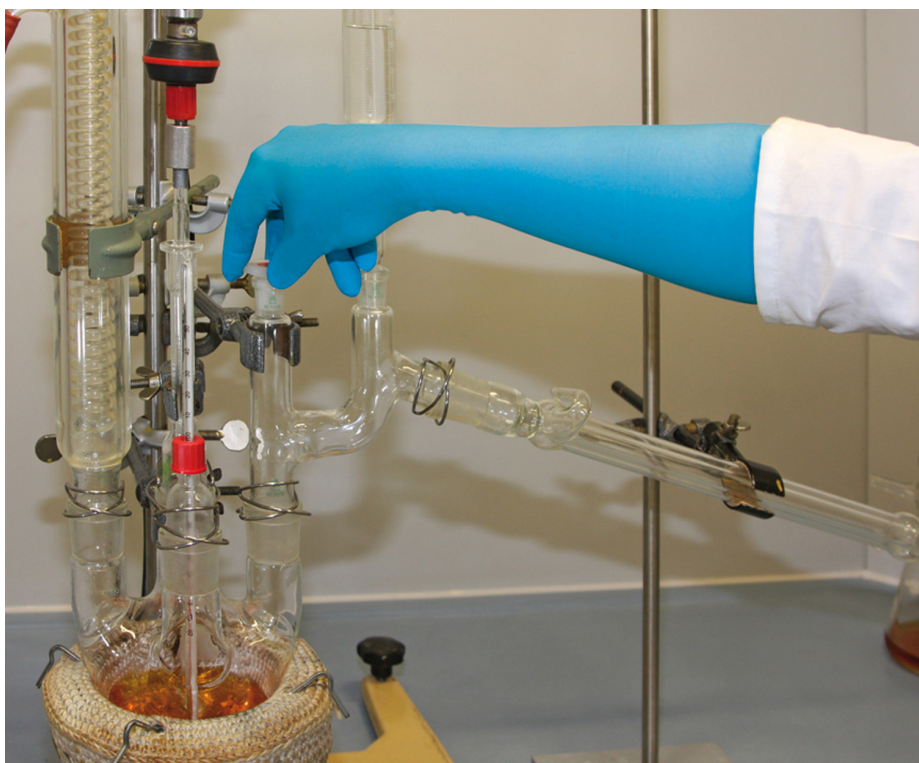

APPLICATION:

- Laboratory and operations
- Chemical industry
- Protection of products
- Biotechnology
- Medical technology
- Pharmaceuticals industry
- Cleaning and maintenance

QUALITIES AND ADVANTAGES:

- Disposable protective glove
- Good chemical resistance
- Very good sensitivity

FEATURES:

- Content 20 pairs in a polybag
- AQL < 0,65
- Free from natural latex
- 400 mm length
- Outstanding wearing comfort due to anatomical design with different fits for the right and left hand
- Food safety according to European Union 1935/2004

ATTRIBUTE	DESCRIPTION / VALUES
Article No.	• 759
Name	• SivoChem® 759
Material	• Special nitrile
Description	• Powderfree
Length (mm)	• 390-410
Total thickness (mm)	• 0,16 ± 0,03
Colour	• Blue
Size	• 7, 8, 9, 10, 11
Classification	• category III EN 374-1/Typ B  KPT EN 374-5  VIRUS 



CHEMICAL PROTECTIVE GLOVES

HONEYWELL PPE

KCL GmbH

Industriepark Rhoen
Am Kreuzacker 9
36124 Eichenzell, Germany
Phone: +49 69 80885425
kclorders@honeywell.com
sps.honeywell.com

Honeywell KCL Sivochem Data Sheet - 07/2022
© 2022 Honeywell International Inc.

Honeywell

