


**A.301MT** A.MT - Micro-Tech® "low torque" screwdriver

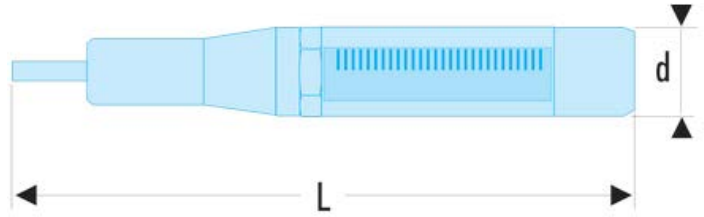

- Lightweight and compact screwdriver for low torque load.
- Right-hand torquing.
- Female hex output for use with bits series 0 - 4 mm (1/4" output with ECR.O drive optionally).
- 82H.4: Adjustment key 4 mm.
- Supplied with calibration certificate and adjustment key.

d [mm]: 23

L [mm]: 130,0

Capacity [cN.m]: 15 - 75

Bits: 1

Graduation: 0,50

Graduation [Cn.m]: 0,5

Outer Size: 1/4"

[g]: 130