




**LED Special E14 T23X53 2W (21W) 200lm 827 Frosted**

Article number: 145120

BAI LED Appliance E14 T23X53mm 220-240V 2W (21W) 200lm 2700K IP22 Frosted Refrigerator Sewing machines LED-lamp

LED lamp suitable for household use, including sewing machines, but also extremely suitable in a refrigerator because of the IP22 value (moisture proof) and shock resistance. Ambient temperature range: -40°C to +40°C.

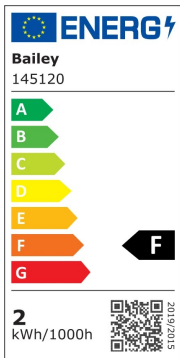

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Special E14 T23X53 2W (21W) 200lm 827 Frosted
Brand	Bailey
Productseries	LED Special
Producttype	Appliance

## ETIM specifications

Socket	E14
Luminous flux [lm]	200 - 200
Nominal voltage [V]	220 - 240
Lamp power [W]	2 - 2
Colour temperature [K]	2700 - 2700
Diameter [mm]	23
Length [mm]	53
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	300 - 300
Colour	White
Type of glass/cover	Frosted
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	200
Power factor	0.5
Lamp efficacy [lm/W]	93
Nominal current [mA]	17 - 17
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP22
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	7500
Weighted energy consumption in 1000 hours [kWh]	2
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

---

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Plastic