


Part Number: 1512125XX

Type	Size	Rating	Description
LED	6mm	12Vac/dc	T-1 <sup>3</sup> / <sub>4</sub> Midget Groove Lamp

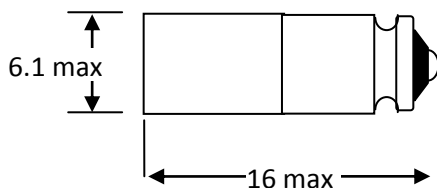

Part #	Colour	Dominant $\lambda$ (nm)	Current (mA)	Intensity (mcd)
1512125UR3	Red	630	15	900 (dc)
1512125UG3	Green	525	16	2000 (dc)
1512125UY3	Yellow	589	15	600 (dc)
1512125B3	Blue	470	16	900 (dc)
1512125W3A	Cool White clear	x=0.31, y=0.32	16	5000 (dc)
1512125W3DA	Cool White diffuse	x=0.31, y=0.32	16	2500 (dc)

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Storage temperature -25 °C to +80°C
- 3 Application temperature -20 °C to +60°C
- 4 Voltage tolerance  $\pm 10\%$
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 The plastic(polycarbonate) has limited chemical resistance
- 7 RoHS & REACH SVHC compliant