



General characteristics

Colour	Grey
IEC degree of protection	IP66 and IP67

Mechanical features

Weight	g	1700
--------	---	------


UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

Ambient conditions

Temperature				
Operating temperature				
	min	°C	-25	
	max	°C	+70	
Storage temperature				
	min	°C	-40	
	max	°C	+85	

Dimensions

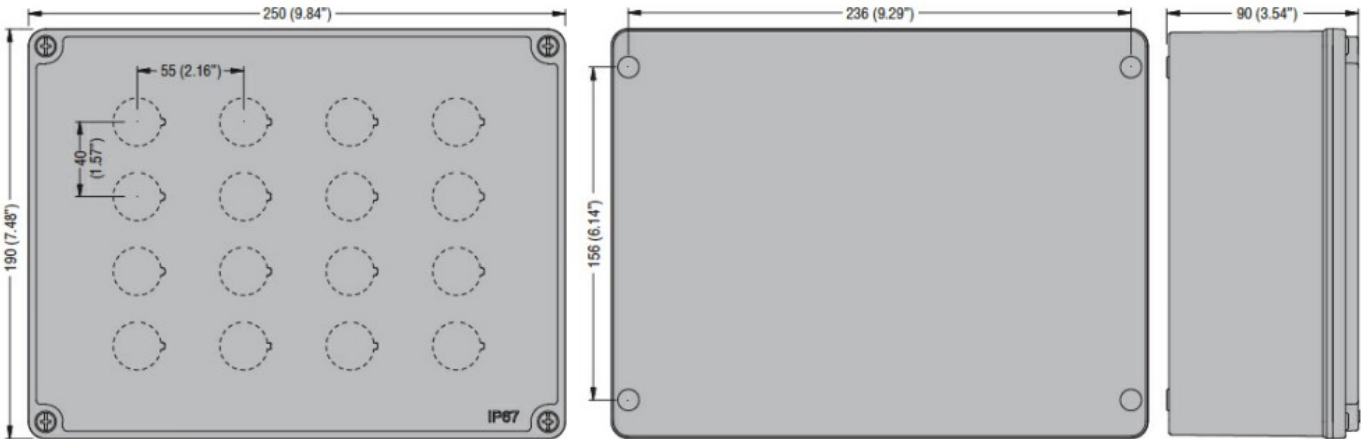

Certifications and compliance

Compliance	IEC/EN 60947-5-1
Certificates	cULus
	EAC

ETIM classification

ETIM 8.0	EC000200 - Enclosure for control circuit devices
----------	--