

LUMIPACK[®] mini

New product

Portable LED security lighting



Characteristics

- Lightweight and ergonomic, 500g
- Robust IK08
- Waterproof IP65
- High autonomy
- Clamp and magnet mounting
- USB plug for mobile charging





Discover **YOUR** LUMIPACK MINI[®]!

TUBE MOUNTING

A double security system ensures the LUMIPACK[®] mini mounting :

Fix it on the magnet, and insert the bracket in the slot !

MOUNTING OPTIONS

Three mounting options are possible :



Magnet



Belt clip



Chest belt



FEATURES

- A** **USB PLUG** : external device charging possibility
- B** **CHARGE CONNECTOR** : input voltage 12VDC
- C** **ON/OFF button**
- D** **Dimming option**: vary the lighting intensity and increase the autonomy

LED INDICATOR

- Green** : indicate the charging end
- Blinking green**: charging in progress
- Blinking red** : optic signal


TUBES CHARACTERISTICS

Model	Tube
Power (W)	2.25
Luminous power (lumen)	330
Luminous efficiency (lm/W)	147
Color temperature (K)	5 000
Color Rendering Index	85
Beam angle (°)	24

MECHANICAL CHARACTERISTICS

Modèle	Tube
Weight (g)	100
Tube dimensions (mm)	Ø 30 L 95
Battery pack weight (g)	300
Battery pack dimensions (mm)	110 x 90 x 45

ENVIRONMENT CHARACTERISTICS

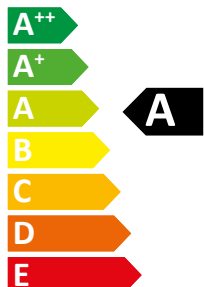

Lifespan (L70)	35 000 hours
Storage temperature	-40°C to 35°C
Charging temperature	10°C to 25°C
Operating temperature	-20°C to 40°C
IP rating	IP65
Energy class	A

BATTERY CHARACTERISTICS

Autonomy* (h)	9h
Voltage (V)	14.4

*Average autonomy for a use with full powered tube and without USB plug used

STANDARDS

In compliance with european norms and directives

CEM Directive 2014/30/UE
DBT Directive 2014/35/UE
RoHs Directive 2011/65/UE

WEEE Directive 2012/19/UE and all relative regulations
ErP Directive 2009/125/CE and all relative regulations

