


PROFESSIONAL R.G.B.+Switch VIDEO CABLE

(for professional video transmission)

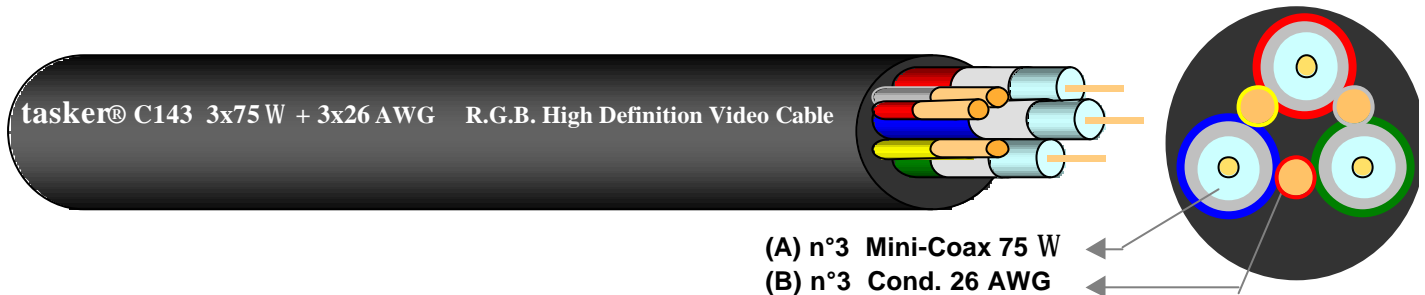

tasker® C143 3x75 W + 3x26 AWG

A) n° 3 Mini-Coaxial shielded cable 75 W

Cond. Sect.: mm² 0,08 (10x0,10 OFC red copper)
Core Covering: PEE – White colour
External Core Ø: mm. 1,5±0,05
Shielded: Spiral 100% - tinned copper
Sheath: PVC
Sheath colour: Red, Green, Blue
External Ø: mm. 2,8±0,05

B) n° 3 Insulated cores 26 AWG

Cond. Sect.: AWG 26 - mm² 0,12
(7x0,15 OFC red copper)
Core Covering: PVC – Grey, Red, Yellow
External Core Ø: mm. 1,0±0,05

External Sheath: **PVC**
Sheath Colour: Black
External Cable Ø: mm. 7,8±0,1

A)

Attenuation db/100mt:

50 MHz	100 MHz	200 MHz	400 MHz	860 MHz
19.5	28.5	35.6	60.0	90.0

Conductor resistance: 210 Ω/Km.±5%

Impedance: 75 Ω±3%

Capacity: 67 pF/mt.

B)

Conductor resistance: 140 Ω/Km.±5%

Cable)

Test Voltage: 1000 V.

Max. Rated Voltage: A.C. 49 V.

Operative temperature: -15°C./+70°C.

Packing:

C143/100

Carton Reels: mt. 100

C143/300

Wood Reels: mt. 300

Cavo professionale flessibile adatto alla trasmissione video **75 W in R.G.B.+Switch** per impianti video e/o di sicurezza di medie distanze.

Questo cavo è consigliato anche per la realizzazione di cavi assemblati con connettori Seriali 9 e 15 Poli, SCART, RCA, BNC ed altri compatibili con il diametro esterno totale del cavo e/o dei coassiali interni.

Cavo consigliato per il collegamento di apparecchi audio/video come ad esempio: Videoregistratori, Videocamere, DVD, Videoproiettori, Monitor, Video-wall, ed altre applicazioni che necessitano di 3 linee Video e/o Audio e relativi switch o controlli.

