



iM2975

Storm

Travel Case

The Peli™ Storm Case™ has the same legendary DNA as our Peli Protector Case, with one primary difference: A unique Press and Pull latch that locks automatically, but open with a light touch. Guaranteed for life, the Peli Storm case is made in the USA and engineered using the finest components.

- Five Press & Pull Latches
- Two Padlockable Hasps
- Two Double-layered, Soft-grip Handles
- Powerful Hinges
- O-ring seal



 
CONFIGURATIONS



iM2975
Standard



iM2975-X0000
No Foam



iM2975-X0002
With Padded Dividers



iM2975-X0001
With Foam



WINE-20B
20-Bottle Wine



WINE-24B
24-Bottle Wine

DIMENSIONS

Interior (L×W×D)	29.00 x 18.00" x 13.80 (73.7 x 45.7 x 35.1 cm)
Exterior (L×W×D)	31.30 x 20.40" x 15.50 (79.5 x 51.8 x 39.4 cm)
Lid Depth	2.00" (5.1 cm)
Bottom Depth	11.80" (30 cm)
Total Depth	13.8" (35.1 cm)
Int Volume	4.17 ft ³ (0.118 m ³)
Padlock Hole Diameter	0.28" (0.7 cm)

MATERIALS

Body	Injection Molded HPX™ high performance resin
Latch	Valox - Polybutylene Terephthalate (PBT)
Latch (Alt)	Xenoy - Polyester/Polycarbonate blend
O-Ring	EPDM
Pins	Stainless Steel
Pins (Alt)	Aluminum
Foam	1.3/1.35 polyester
Purge Body	Valox - Polybutylene Terephthalate (PBT)
Purge Body (Alt)	Xenoy - Polyester/Polycarbonate blend
Purge Vent	Gortex membrane

COLOURS

Black	OD Green
-------	----------

WEIGHT

Weight With Foam	29.50 lbs (13.38 kg)
Weight Empty	22.80 lbs (10.34 kg)
Buoyancy	250.02 lbs (113.41 kg)
Master Pack Weight	31.50 lbs (14.29 kg)

TEMPERATURE

Minimum Temperature	-20°F (-28.9 °C)
Maximum Temperature	140°F (60 °C)


CERTIFICATIONS

IP67

OTHER

Extendable Handle	yes
Master Pack	1
Military	yes

ACCESSORIES

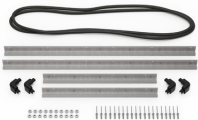				
iM29XX-UTILITYORG Utility Organizer	iM2975-FOAM 8 pc. Replacement Foam Set	iM-LIDSTAY Lid Stay	1506TSA TSA Lock	1500D Desiccant Silica Gel
				
iM2975-M4-BEZEL Base Bezel Kit (Metric)	iM2975-M4-BEZEL-L Lid Bezel Kit (Metric)			