

REDUC-M-KV-M32/M25 - Reducing adapter



1647637

<https://www.phoenixcontact.com/gb/products/1647637>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Reducing adapter, connecting thread: M32 x 1.5, color: silver-colored, with O-ring



Product description

Reduced M32 to M25

Commercial data

| | |
|--------------------------------------|---------------------|
| Item number | 1647637 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | AF7DZX |
| Product key | AF7DZX |
| Catalog page | Page 700 (C-2-2019) |
| GTIN | 4017918941536 |
| Weight per piece (including packing) | 34.95 g |
| Weight per piece (excluding packing) | 34.95 g |
| Customs tariff number | 74198090 |
| Country of origin | DE |

REDUC-M-KV-M32/M25 - Reducing adapter



1647637

<https://www.phoenixcontact.com/gb/products/1647637>

Technical data

 
Product properties

| | |
|--------------|------------------|
| Product type | Reducing adapter |
| Seal present | yes |

Connection data

| | |
|-------------------|--------------|
| Tightening torque | 11 ... 12 Nm |
|-------------------|--------------|

Dimensions

| | |
|----------------------------------|--|
| Dimensional drawing |  |
| Width | 37.00 mm |
| Length | 11.5 mm |
| Length of the connecting thread | 8 mm |
| Length without connecting thread | 3.5 mm |
| Diameter | 32 mm |
| Connecting thread diameter | 32 mm |
| Hexagon angular dimension | 37 mm |
| Thread type connection side | M32 x 1.5 |
| Thread pitch | 1.5 mm |
| Thread type on seal side | M25 |

Material specifications

| | |
|--------------------------|----------------------|
| Color | brass color |
| Material | Brass, nickel-plated |
| Seal material | NBR |
| Housing surface material | Ni |

Cable/line

| | |
|--------------|----|
| Halogen-free | no |
|--------------|----|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|---|
| Degree of protection | IP65 (Depends on the screw connection used) |
| Ambient temperature (operation) | -20 °C ... 80 °C |

Mounting

| | |
|---------------|---|
| Assembly note | With corresponding screw connection: IP68 |
|---------------|---|


REDUC-M-KV-M32/M25 - Reducing adapter

1647637

<https://www.phoenixcontact.com/gb/products/1647637>

Drawings

Dimensional drawing

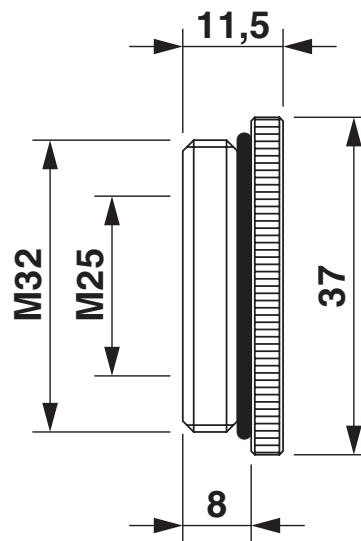

Dimensional drawing

REDUC-M-KV-M32/M25 - Reducing adapter



1647637

<https://www.phoenixcontact.com/gb/products/1647637>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27140806 |
|-------------|----------|

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC000938 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

REDUC-M-KV-M32/M25 - Reducing adapter



1647637

<https://www.phoenixcontact.com/gb/products/1647637>

Environmental product compliance

EU RoHS

| | |
|---|------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(c) |

China RoHS

| | |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50 |
| | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | a686d5eb-0ec5-4947-a9f9-1a0714eaa4d8 |

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk