


QT | Cable grommets for QUICK systems

for cable diameters 1 - 15 mm / IP54

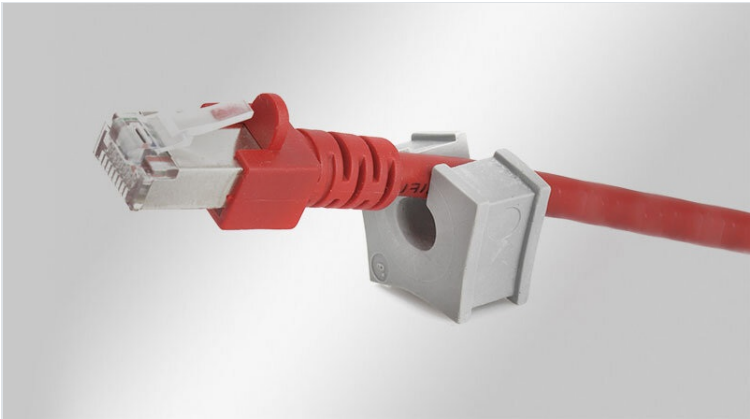

The QT range supports cable diameters from 1 to 15 mm. They are used with the following cable entry frames:

- [KEL-QUICK](#)
- [QVT](#)
- [QVT-CLICK](#)
- [KEL-QTA](#)

QT grommets enable a sealing of the cables with IP54.

When using double or quadruple grommets the cable density of cable entry frames and cable glands can be greatly increased. The multi-hole model range QT is designed for cable diameters from 1 to 6 mm. icotek also offers special cable grommets for e.g. ASI lines.

When installing the QT grommets in multiple rows, the flat sides should be facing each other. This allows the flat sides to match up and provide a secure seal.



Specifications

IP rating (EN 60529)	IP54
Material	Elastomer
Flame class	UL94-V0, self-extinguishing
Operating temperature	-40 C° to 100 C°
Properties	silicone free, halogen free

Advantages & benefits


- Enable routing of pre-terminated cables through cable entry frames and split cable glands
- Available for a large range of cable diameters
- Greatly increased cable density when using double or quadruple grommets

Product types & sizes

QT 1	Part No.	42501	Height	12 mm
	EAN	4251269318184	Mounting height	2 mm
	Package quantity	10	For cable type	Round cable
	For max. no. of cables	1	Clamping range	1 x 1 - 2 mm
	Colour	grey (similar RAL 7035)		
	Length	19 mm		
	Width	20 mm		
IP54				

QT 2	Part No.	42502	Height	12 mm
	EAN	4251269318191	Mounting height	2 mm
	Package quantity	10	For cable type	Round cable
	For max. no. of cables	1	Clamping range	1 x 2 - 3 mm
	Colour	grey (similar RAL 7035)		
	Length	19 mm		
	Width	20 mm		
IP54				


QT 3

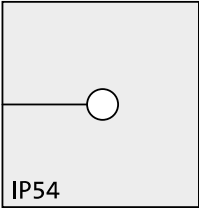

Part No. **42503**
EAN **4251269308734**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 3 - 4 mm**


QT 4

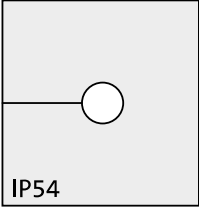

Part No. **42504**
EAN **4251269308741**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 4 - 5 mm**


QT 5

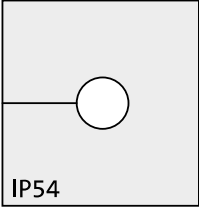

Part No. **42505**
EAN **4251269308758**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 5 - 6 mm**


QT 6

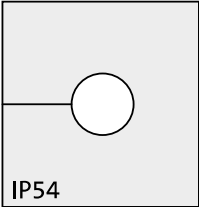

Part No. **42506**
EAN **4251269308765**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 6 - 7 mm**


QT 7

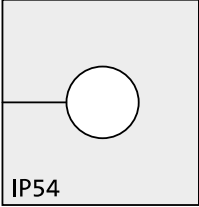

Part No. **42507**
EAN **4251269308772**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**







Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 7 - 8 mm**

QT 8

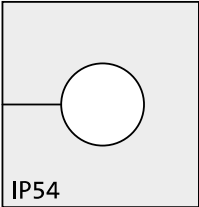


Part No. **42508**
EAN **4251269308789**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **1 x 8 - 9 mm**

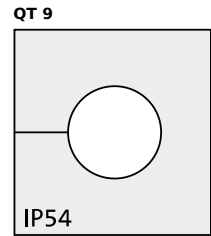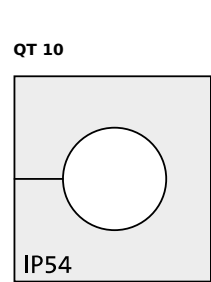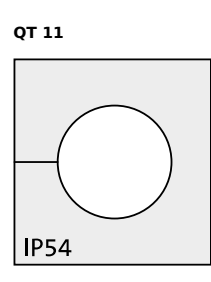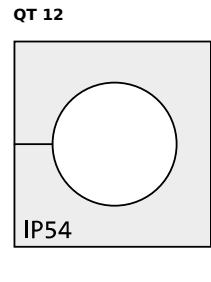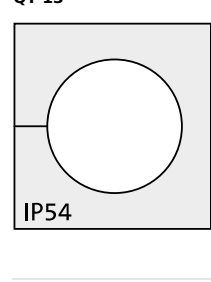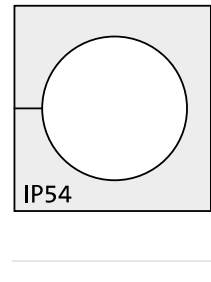QT 9 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42509 4251269308796 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 9 - 10 mm
QT 10 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42510 4251269308802 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 10 - 11 mm
QT 11 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42511 4251269308819 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 11 - 12 mm
QT 12 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42512 4251269308826 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 12 - 13 mm
QT 13 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42513 4251269308833 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 13 - 14 mm
QT 14 	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42514 4251269308840 10 1 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 1 x 14 - 15 mm


QT 2|3

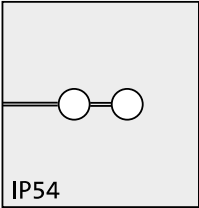

Part No. **42566**
EAN **4251269308864**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 3 - 3 mm**


QT 2|4

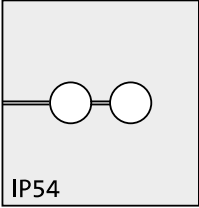

Part No. **42568**
EAN **4251269308871**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 4 - 4 mm**


QT 2|5

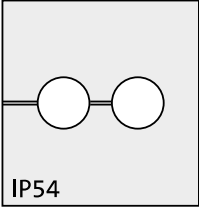

Part No. **42570**
EAN **4251269308888**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 5 - 5 mm**


QT 2|5.5

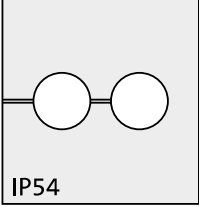

Part No. **42571**
EAN **4251269308895**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 5.5 - 5.5 mm**


QT 2|6

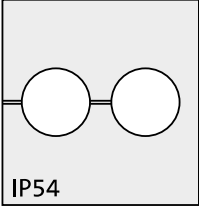

Part No. **42572**
EAN **4251269308901**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**







Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 6 - 6 mm**


QT 2|6.5

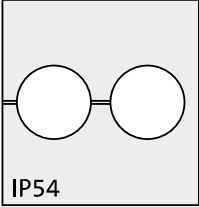

Part No. **42576**
EAN **4251269308949**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**


Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **2 x 6.5 - 6.5 mm**

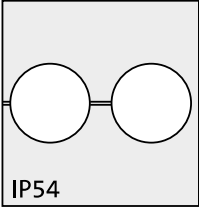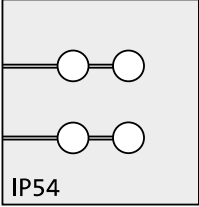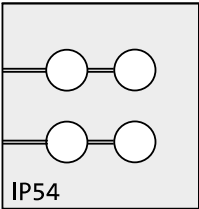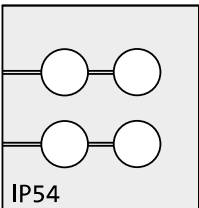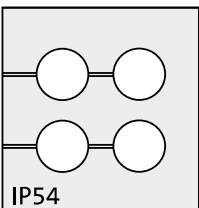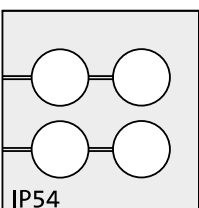QT 2 7  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42578 4251269308956 10 2 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 2 x 7 - 7 mm
QT 4 3  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42580 4251269308963 10 4 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 4 x 3 - 3 mm
QT 4 4  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42582 4251269308970 10 4 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 4 x 4 - 4 mm
QT 4 4.5  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42583 4251269308987 10 4 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 4 x 4.5 - 4.5 mm
QT 4 5  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42584 4251269308994 10 4 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 4 x 5 - 5 mm
QT 4 5.5  IP54	Part No. EAN Package quantity For max. no. of cables Colour Length Width	42585 4251269309007 10 4 grey (similar RAL 7035) 19 mm 20 mm	Height Mounting height For cable type Clamping range	12 mm 2 mm Round cable 4 x 5.5 - 5.5 mm

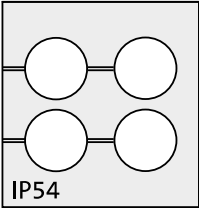


Part No. **42586**
EAN **4251269309014**
Package quantity **10**
For max. no. of cables **4**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Round cable**
Clamping range **4 x 6 - 6 mm**

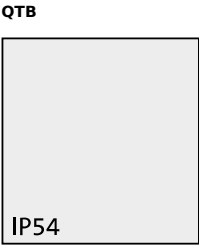


Part No. **42540**
EAN **4251269308857**
Package quantity **10**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**
Height **12 mm**

Mounting height **2 mm**
Blank grommet **1**

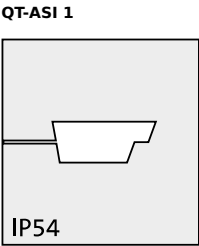


Part No. **42573**
EAN **4251269308918**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **ASI cable**

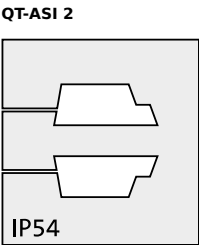

Part No. **42574**
EAN **4251269308925**
Package quantity **10**
For max. no. of cables **2**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **ASI cable**

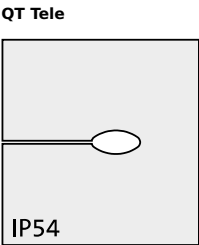

Part No. **42575**
EAN **4251269308932**
Package quantity **10**
For max. no. of cables **1**
Colour **grey (similar RAL 7035)**
Length **19 mm**
Width **20 mm**

Height **12 mm**
Mounting height **2 mm**
For cable type **Telephone cable**